



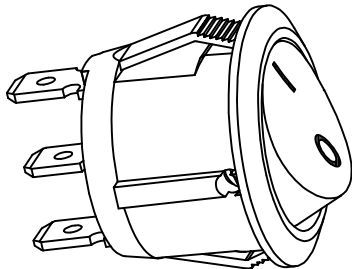

MR-5

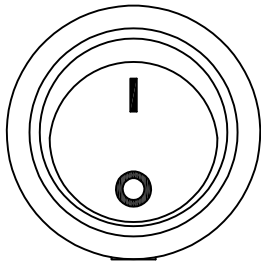

Rating: 10A 125V AC (UL CUL)  

6A 250V AC (UL CUL TUV CB) 



Contact Resistance: 50mΩ Max

Insulation Resistance: DC 500V 100MΩ Min


Dielectric Strength: AC1500V 1 minute

Electrical life: 10,000 cycles

Operating Temperature: 0°C~85°C

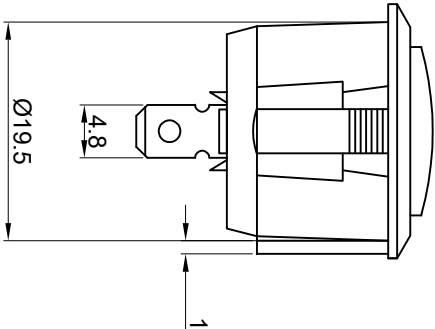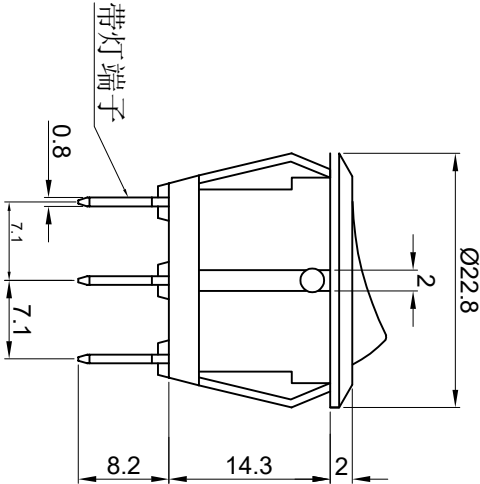

CUT-OUT

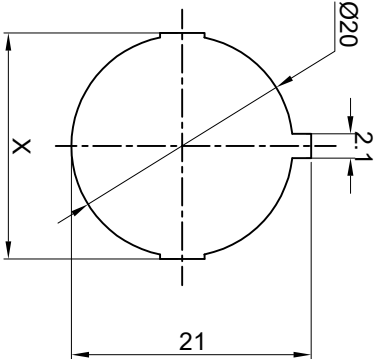


	X
0.75~1.25	20.2
1.25~2.00	20.4
2.00~3.00	20.6

MATERIAL:

Body:Nylon66,UL rated:94V-2 min

Actuator:PC

Terminal:Brass,silver or tin plated

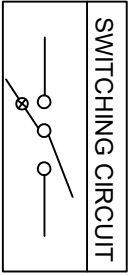

X	0	1	2	3	4	5	6	7	11
Marking	None								

		公差 TOLERANCES		$X \pm 0.3$	$.XX \pm 0.15$	角度	$\pm 1^\circ$	单位 DIMENSION UNIT	mm.
		版本 VERSION	A1	比例尺 SCALE	NONE	日期 DATE	2020.12.28	品名 TITLE	图号 DRAWING NO
		核准		核对	Z. H. B.	绘图 DATE	王立权	MR-5-110-CSL-BR	MR-5-110-CSL-BR_A1
版本 VER	变更说明 CHANGE DESCRIPTION	日期 DATE	ECN NO.	APPROVED BY	CHECKED BY	DRAWN BY			