

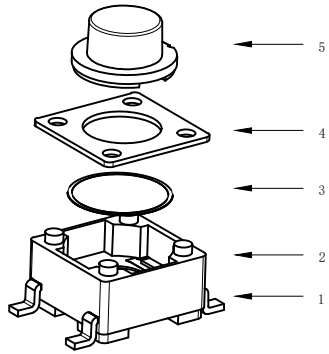
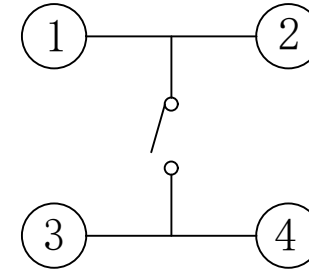
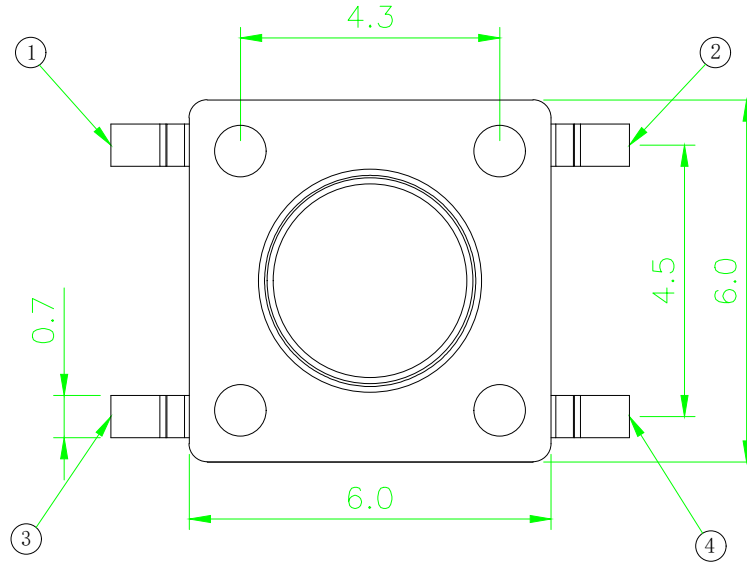


Specification

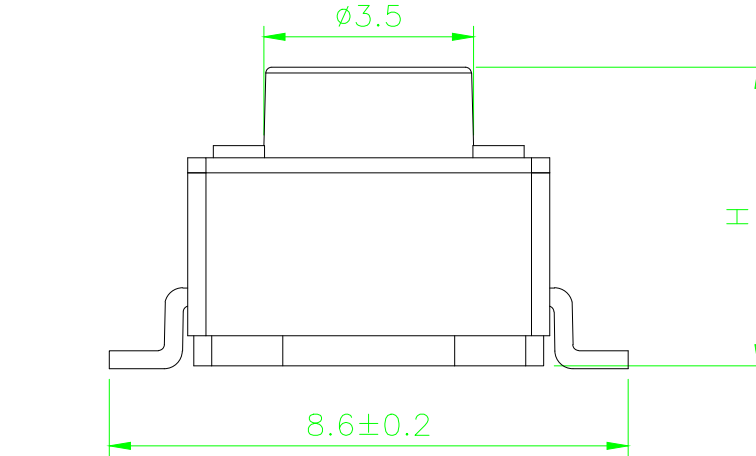

CIRCUIT DIAGRAM

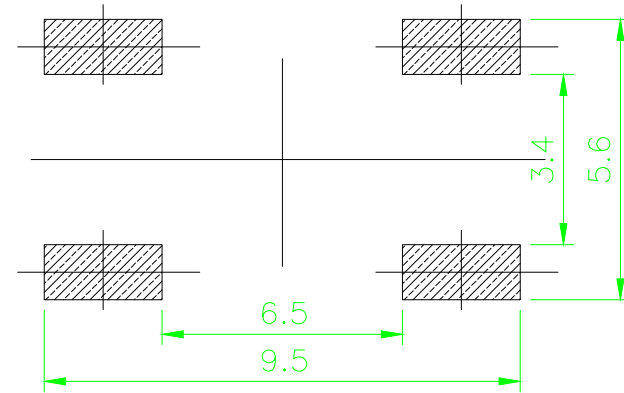

PCB. WELDING DRAWING

Operating Life	100,000
Contact rating	50mA@12V DC.
Insulation resistance	100MΩ min.
Contact resistance	100mΩ max. initial.
Dielectric Strength	250 V AC(1mn)
Travel	0.2±0.1mm
Storage Temperature	- 30° C to 85° C

Mechanical

ITEM	DESCRIPTION	MATERIAL	QTY	FINISH/COLOR
E	Button	PPA	1	Black
D	COVER	Brass	1	Cleaning
C	DOME	Stainless Steel	1	Plated Ag
B	HOUSING	PPA	1	Black
A	PIN	PHOSPHOR BRONZE	1	Plated Ag

Type	Operating Force (gf)	Height (mm)	Button Shape (G, J, T)	Leads Ground pin (0, 1)	Pogo Option (0, 1)
YTS1R003	2 (250±50) 1 (180±50) 0 (100±30)	S 14	B (BLACK)	G	0 (None)
		Q 15.0			
		P 13.0			
		O 12.0			
		N 11.0			
		M 10.0			
		R 9.5			
		L 9.0			
		K 8.5			
		J 8.0			
		H 7.5			
		G 7.0			
		F 6.5			
		E 6.0			
		D 5.5			
		C 5.0			
		B 4.5			
		A 4.3			

X. ±0.50	X.° ±2°	UNITS mm
.X ±0.30	.X° ±1°	MAT'L
.XX ±0.10	.XX° ±0.5°	
.XXX ±0.05		FINISH
THESE DRAWINGS AND SPECIFICATIONS ARE THE PROPERTY OF YIYUAN TECHNOLOGY CO.,LTD AND SHALL NOT BE REPRODUCED, COPIED OR USED IN ANY MANNER WITHOUT THE PRIOR WRITTEN CONSENT OF YIYUAN TECHNOLOGY CO.,LTD Email at info@yiyuanswitches.com		
Q'TY		



深圳市怡远科技有限公司
SHENZHEN YIYUAN TECHNOLOGY CO., LTD

PART NO.
YTS1R003

 
TITLE:
TACTILE SWITCH 6*6 SMT

APPD: ROGER

CHKD: ROC

DR: BILLY WANG 2020/08/21

DWG NO. :
YTS1R003



SCALE	SHEET	REV.
1/1	1/1	A1

Packaging:
A reel of 1000 pieces for 4.3~6.5H
A reel of 800 pieces for 7.0~7.5H
A reel of 700 pieces for 8.0~8.5H
A reel of 500 pieces for 9.0~15.0H