



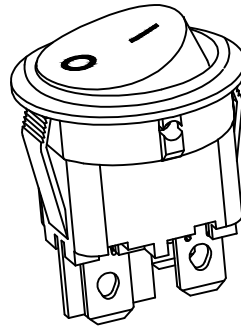

MR-6A

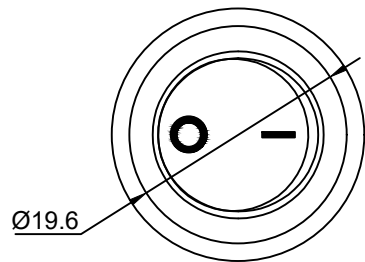

Rating: 10A 125V AC (UL CUL) 
6A 250V AC (UL CUL TUV) 



Contact Resistance: 50mΩ Max

Insulation Resistance: DC 500V 100MΩ Min


Dielectric Strength: AC1500V 1 minute

Electrical life: 10,000 cycles

Operating Temperature: -20°C~85°C

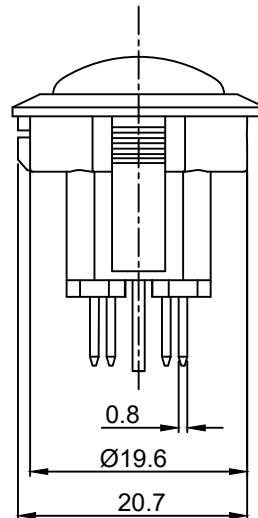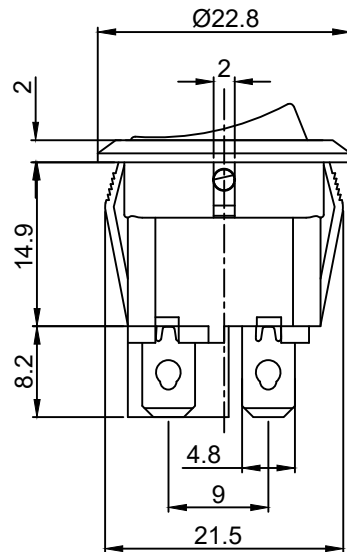

CUT-OUT

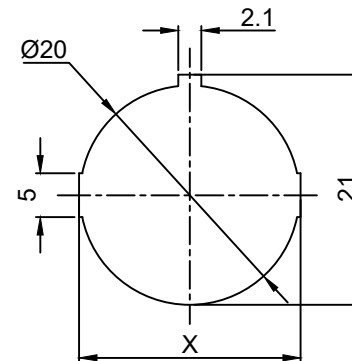

	X
0.75~1.25	20.2
1.25~2.00	20.4
2.00~3.00	20.6

 
MATERIAL:

Body:Nylon66,UL rated:94V-2 min

Actuator:Nylon66,UL rated:94V-2 min

Terminal:Brass,silver or tin plated

SWITCHING CIRCUIT



X	0	1	2	3	4	5
Marking	None					

				公差 TOLERANCES		.X± 0.3	.XX± 0.15	角度 ANGLE± 1°		单位 DIMENSION UNIT		mm.
				版 本 VERSION	A1	比 例 尺 SCALE	NONE	日 期 DATE	2022.06.27	品 名 TITLE		图 号
										DRAWING NO		
				核 准		核 对	Z.H.B.	绘 图	Z.H.B.	MR6A-210-C5N-BB		
版本 VER.	变 更 说 明	CHANGE DESCRIPTION	日期 DATE	ECN NO.	APPROVED BY	CHECKED BY		DRAWN BY				MR6A-210-C5N-BB_A1