


- High Common Mode Impedance at High Frequency.
- Excellent Noise Suppression Performance.
- Small Size and Low Profile, Surface Mount Type.
- Operating Temperature Range: -40°C to +85°C.
- RoHS Compliant.




Electrical Specifications @25°C

Part Number	Common Mode Impedance	DC Resistance	Rated Current	Rated Volt	Insulation Resistance
	Ω , @100MHz	Ω Max	mA Max	Vdc Max	M Ω Min
CC2012F-601	600 $\pm$ 25%	0.88	300	50	10


MECHANICAL DIMENSIONS (unit:mm)

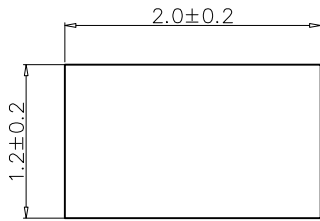


TOP VIEW

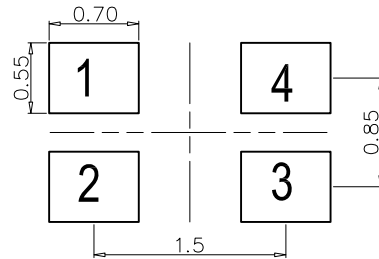

SUGGEST LAYOUT

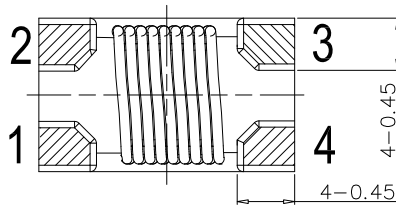


BOTTOM VIEW

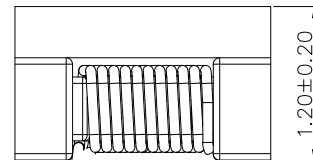

SIDE VIEW

Unless otherwise specified all tolerances are: ± 0.25 mm

SCHEMATIC

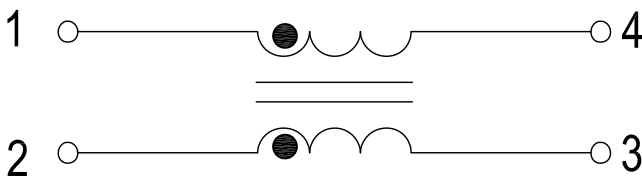

Impedance Frequency

