


產品編碼 P/N	PSPMAA0412~2213 Series	測試設備 TEST INSTRUMENT	Chroma 3302 16502
產品系列 Series	一体成型电感	測試頻率 TEST FREQUENCY	100KHZ/1V

封裝尺寸
Dimension (mm)

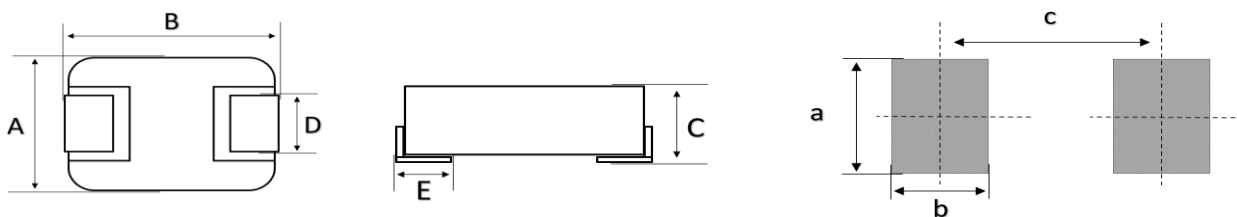

系列	封裝尺寸 Dimension					焊盤尺寸 Land Pattern		
Series	A	B	C	D	E	a	b	c
0618	6.6±0.3	7.1±0.3	1.8MAX	3.0±0.5	1.6±0.5	3.5Typ	2.1Typ	5.8Typ
0602	6.6±0.3	7.1±0.3	2.0MAX	3.0±0.5	1.6±0.5	3.5Typ	2.1Typ	5.8Typ

0610~0602 Series

產品編碼 P/N	@ 25 °C Ambient Temperture					
	感值	公差	DCR		溫升電流 (IRMS)	飽和電流 (ISAT)
	Inductance	Tolerance	mΩ		A	A
	μH	±	Typ	Max	ΔT≈40℃	L0 drop≈30%
PSPMAA0618-R22M-ANP	0.22	20%	5.3	5.7	14.0	26.0
PSPMAA0618-R33M-ANP	0.33	20%	6.6	7.0	12.0	18.0
PSPMAA0618-R47M-ANP	0.47	20%	8.4	9.3	11.0	18.0
PSPMAA0618-R68M-ANP	0.68	20%	12.7	13.9	9.0	17.0
PSPMAA0618-R82M-ANP	0.82	20%	13.8	15.9	8.0	17.0
PSPMAA0618-1R0M-ANP	1.00	20%	17.5	18.3	7.0	14.0
PSPMAA0618-1R5M-ANP	1.50	20%	32.6	34.0	5.5	11.5
PSPMAA0618T-2R2M-ANP	2.20	20%	40.3	46.0	4.8	10.0
PSPMAA0618-3R3M-ANP	3.30	20%	44.0	49.0	4.6	6.8
PSPMAA0618-4R7M-ANP	4.70	20%	76.6	78.0	3.0	6.0
PSPMAA0602-R10M-ANP	0.10	20%	2.5	3.5	16.0	30.0
PSPMAA0602-R33M-ANP	0.33	20%	5.6	6.8	13.0	24.0
PSPMAA0602-R47M-ANP	0.47	20%	6.4	8.0	10.0	22.0
PSPMAA0602-R68M-ANP	0.68	20%	10.0	12.7	7.5	14.0
PSPMAA0602-1R0M-ANP	1.00	20%	16.0	19.2	7.0	12.0
PSPMAA0602-1R5M-ANP	1.50	20%	26.0	32.0	5.5	10.0
PSPMAA0602-2R2M-ANP	2.20	20%	32.0	36.0	5.0	9.0
PSPMAA0602-3R3M-ANP	3.30	20%	65.0	78.0	4.5	7.0
PSPMAA0602-4R7M-ANP	4.70	20%	73.0	88.0	3.5	5.0
PSPMAA0602-6R8M-ANP	6.80	20%	114.0	140.0	3.0	4.0
PSPMAA0602-100M-ANP	10.00	20%	147.0	180.0	2.0	3.5

