



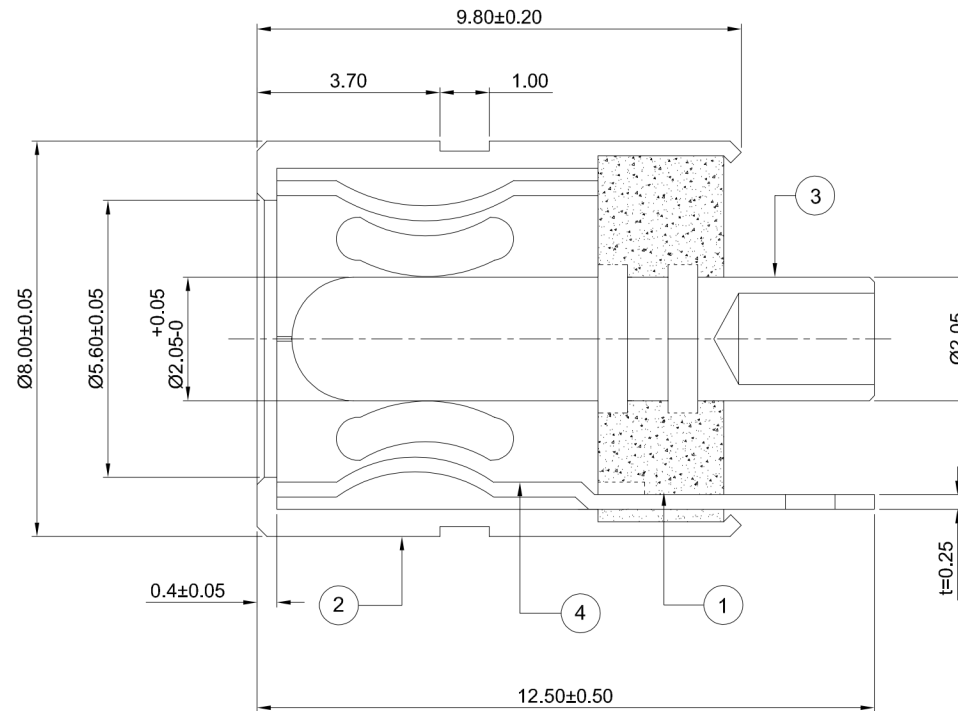

1. Operating temperature range: -40°C ~ +85°C
2. Rated load: 15A 24V DC.
3. Insulation resistance: 100MΩ min
4. Withstand voltage: 500V AC/min
5. Contact resistance: 30mΩ max
6. Durability cycle: 5000 Cycles
7. Insertion and extraction force: 3-30N

1	BASE	HIGH TEMPERATURE PLASTIC	PBT BLACK
2	SHELL	BRASS(C3604)	Ni PLATING
3	PIN	BRASS(C3604)	Ni PLATING
4	CONTACT	BRASS(C5191)	Ni PLATING
NO.	PART NAME	MATERIAL	REMARK

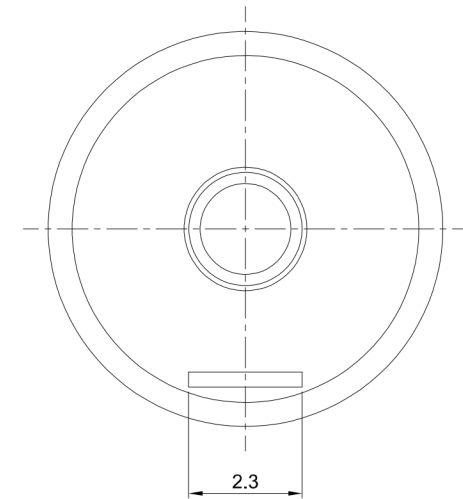

RoHS
Compliant
EU RoHS Standards



SCALE: 1:1	UNIT: mm	Title: Soldered Type DC Power Jack 5521 L=9.8 Ø2.05mm			
SIZE: A4					
Unless otherwise General tolerance: X ±0.40 X.x ±0.30 X.xx ±0.20 X° ±5° X.x° ±3°		Molde Code: DC-S016A-D020-15A			
		DRAWN	CHECKED	APPROVED	DATE
		Xia	Chen	Chen	2023.02.01

