

材料Material

原料Insulator:PBT (UL 94V-0)

相关材料Related Material: Brass

表面涂层Surface Coating: Au Over Ni

规格Specification

额定电流Current rating:2.5AMP

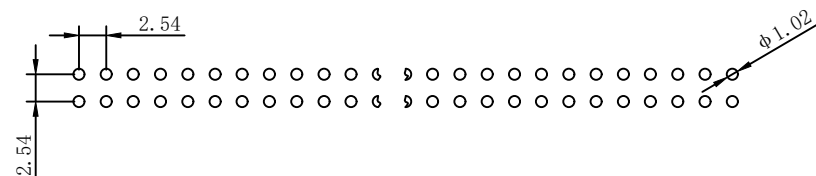
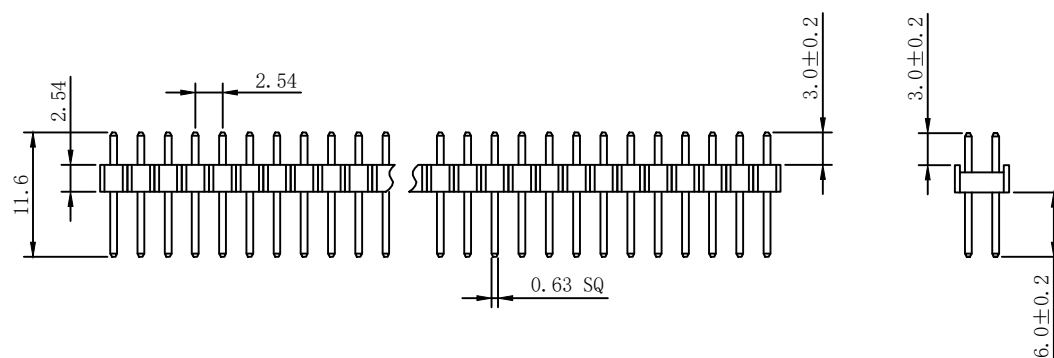
耐压Dielectric Withstanding Voltage:1000v Ac Min

绝缘电阻Insulation Resistance:1000M Ω min

接触电阻Contact resistance:20M Ω Max

工作温度Working Temperature: $-40^{\circ}\text{C} \sim +105^{\circ}\text{C}$

Max. Processing Temp瞬时温度:

PBT $230^{\circ} \pm 5^{\circ}$ 10S

				Shanghai Zhouri Electronics CO.,LTD			
				上海康司玛电子科技有限公司			
				Shanghai Consma Electronic Technology Co., Ltd			
绘图:	牛万龙	日期:	20250626	tel:021-51571121		http://www.zhouri.net	
				fax:021-51571120		http://www.ksmchina.com	
审核:	张海娜	日期:	20250626				
版本号:	ZRLCGY2025-06-26-CJ A/2			产品名称:		2.54- 2*N	
第三视角:		单位:	mm	比例:	图幅:	A4	页次 共 01 第 01