


产 品/Product : **H200 Rubber SMA-J ,433M Antenna**

料 号/PN : **AH1G.107**

应 用/Application : ISM 433MHz system, LoRa / Remote /Transfer /Recciever ;

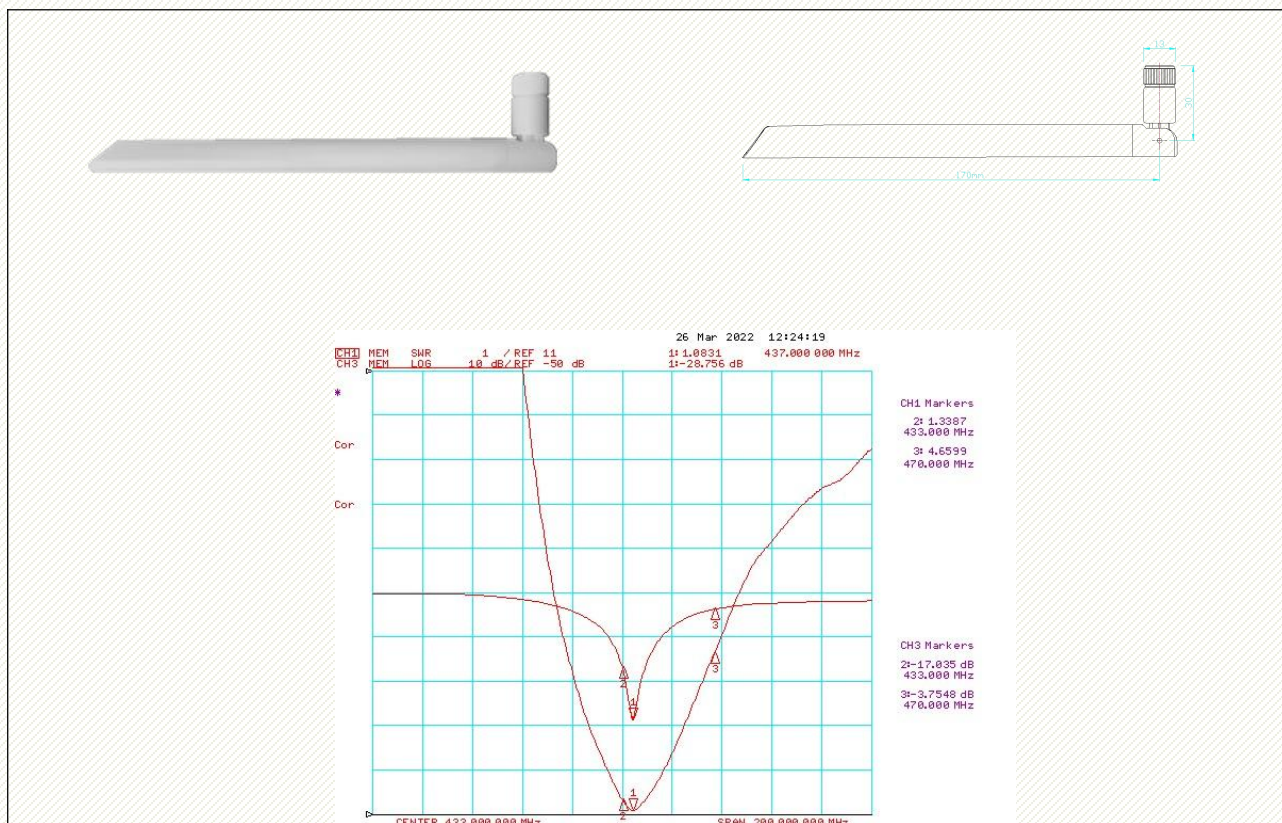

电气参数(Electrical Properties)

频率/Frequency:	433 MHz
输入阻抗/Impedance:	50 Ω
驻波比/VSWR:	≤ 1.5
增益/Gain:	2~3.0 dBi
极化方式/Polarization:	Vertical / Omni

机械参数(Mechanical Properties)

接头&线缆/Conn&Cable:	SMA-J
材料&颜色/Material&Color:	Copper / ABS
安装方式/Mounting:	SMA connector
尺寸/Size:	$\phi 13 \times H200$ mm
重量/Weight:	11.0 g/pcs
工作温度/Operate Temp:	-40 ~ +85 $^{\circ}\text{C}$

关联产品/Relation Product



SMA-K DIP ([AHCG.202](#))



SMA-K ASSY ([AHCG.101](#))



H175 Rubber Magnetic
([AH1G.401](#))





H200 FiberGlass ([AH1G.501](#))

产品手册/ Product Catalogue



下载地址/Download Link: <http://docs.AntennaHome.com/ant/catalogue.pdf>

免费样品申请
Ask free sample

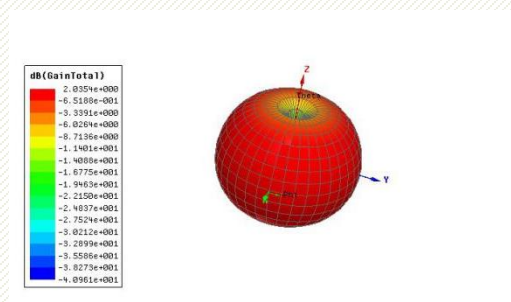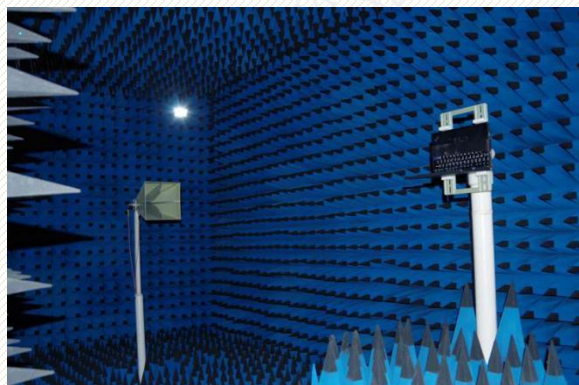

Online Support

Contact Us

E-mail : CS@AntennaHome.com

Website : [Http://www.AntennaHome.com](http://www.AntennaHome.com)