


产 品/Product : **H170 Rubber SMA-J, 868MHz 915MHz 824~928MHz LoRa Antenna**

料 号/PN : **AH1G.109**

应 用/Application : ISM Sub-1GHz, includes frequencies of 868MHz, 915MHz wireless products

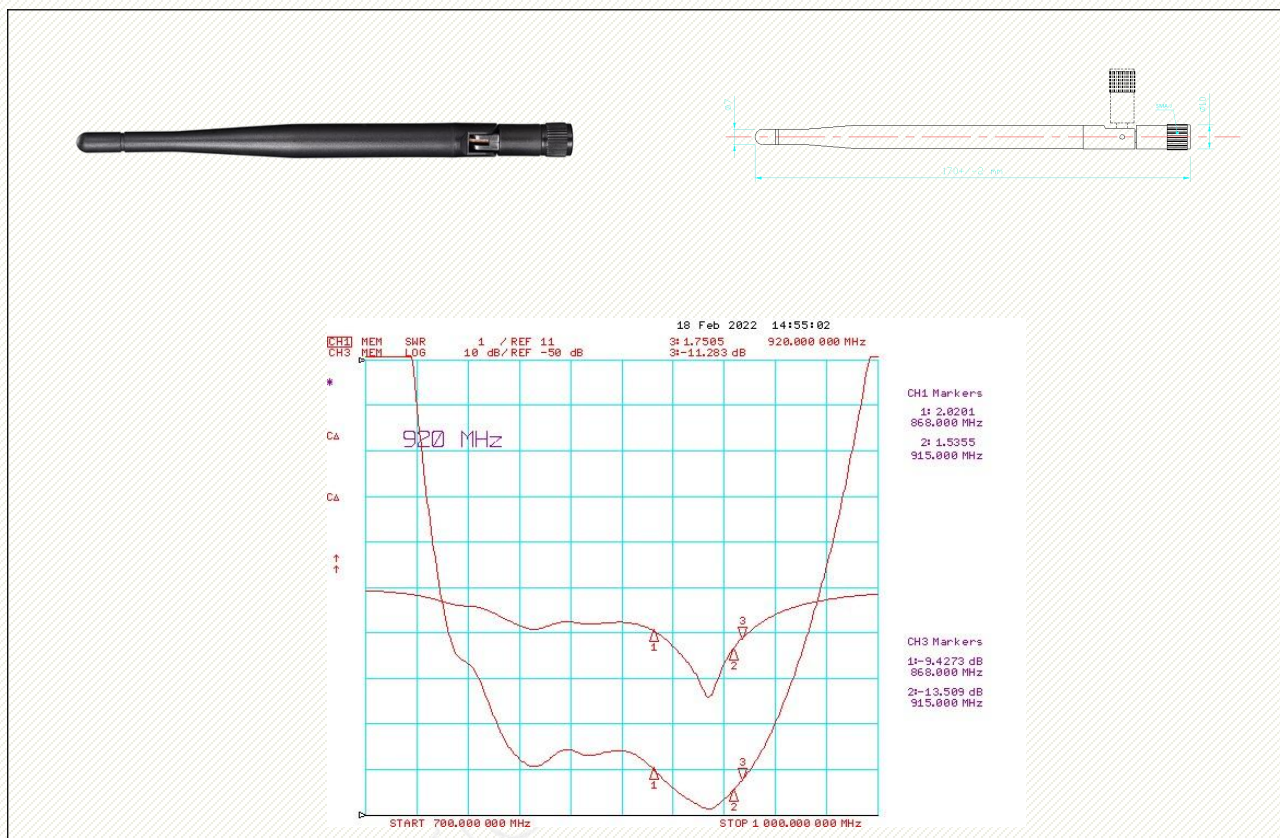

电气参数(Electrical Properties)

频率/Frequency:	868MHz, 915MHz, 824~928MHz
输入阻抗/Impedance:	50 Ω
驻波比/VSWR:	≤ 2.0
增益/Gain:	3.0 dBi
极化方式/Polarization:	Vertical / Omni

机械参数(Mechanical Properties)

接头&线缆/Conn&Cable:	SMA-J
材料&颜色/Material&Color:	Copper / ABS
安装方式/Mounting:	SMA connector
尺寸/Size:	$\phi 13 \times H195$ mm
重量/Weight:	16.0 g/pcs
工作温度/Operate Temp:	-40 ~ +85 $^{\circ}\text{C}$

关联产品/Relation Product



SMA-K DIP ([AHCG.202](#))



SMA-K ASSY ([AHCG.101](#))



PCB 2.4G ([AH2G.201](#))





H200 FiberGlass ([AH2G.501](#))

产品手册/ Product Catalogue



下载地址/Download Link: <http://docs.AntennaHome.com/ant/catalogue.pdf>

免费样品申请
Ask free sample

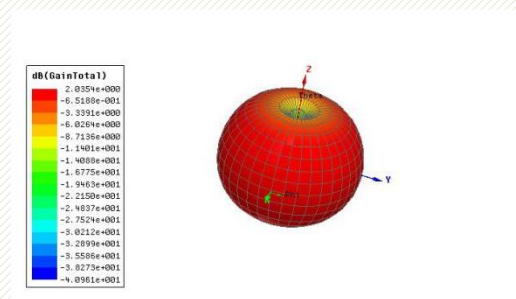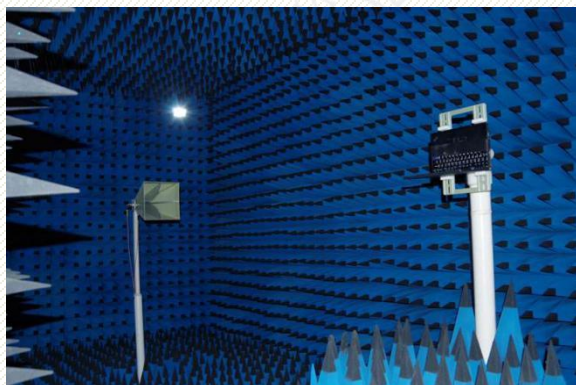

Online Support

Contact Us

E-mail : CS@AntennaHome.com

Website : [Http://www.AntennaHome.com](http://www.AntennaHome.com)