


产 品/Product : **Spring DIP, 868/915M, Antenna**

料 号/PN : **AH1G.312B**

应 用/Application : **LoRa 868/915M , ISM,Sub-1G,LoRa,LoRaWAN ISM Transfer /Recciever ;**

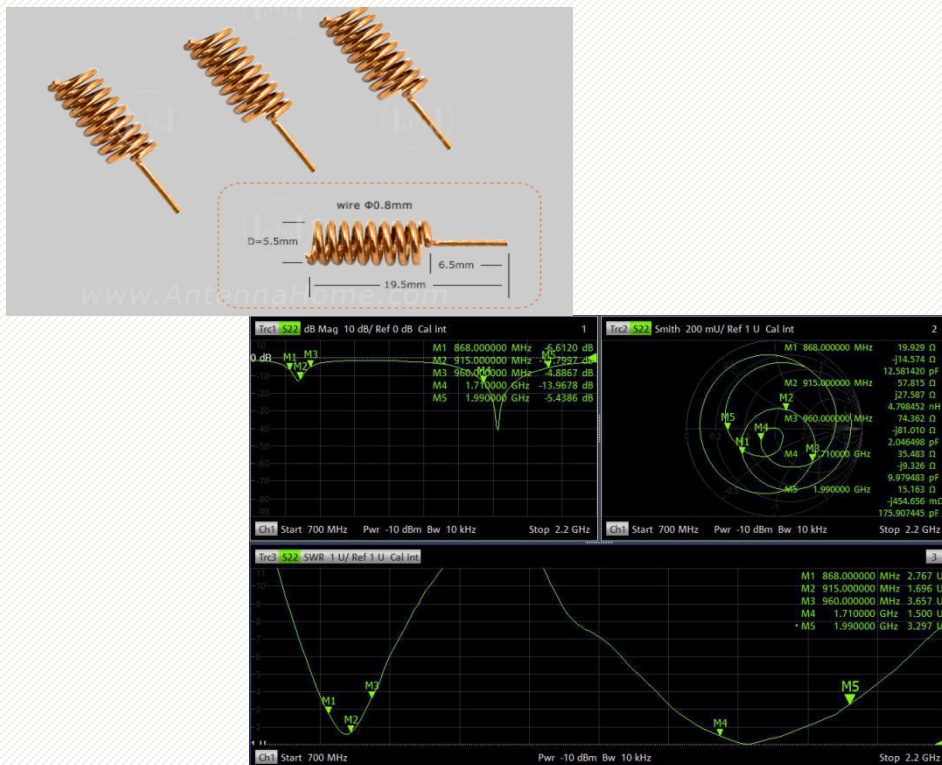

电气参数(Electrical Properties)

频率/Frequency:	868/915 MHz, 900/180MHz
输入阻抗/Impedance:	50 Ω
驻波比/VSWR:	≤ 2.5
增益/Gain:	1.0 dBi
极化方式/Polarization:	Vertical / Omni

机械参数(Mechanical Properties)

接头&线缆/Conn&Cable:	/
材料&颜色/Material&Color:	Copper / ABS
安装方式/Mounting:	DIP
尺寸/Size:	$\phi 5.5 \times L19.5\text{mm}$
重量/Weight:	0.7 g/pcs
工作温度/Operate Temp:	-40 ~ +85 $^{\circ}\text{C}$

关联产品/Relation Product



H50 Rubber ([AH1G.102](#))



PCB IPX ([AH1G.202](#))



H175 Rubber Magnetic
([AH1G.401](#))





H200 FiberGlass ([AH1G.501](#))

产品手册/ Product Catalogue



下载地址/Download Link: <http://docs.AntennaHome.com/ant/catalogue.pdf>

免费样品申请
Ask free sample

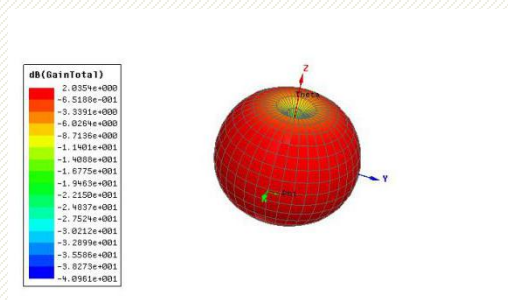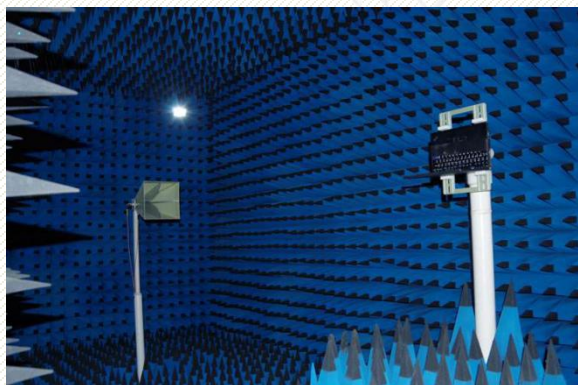

Online Support

Contact Us

E-mail : CS@AntennaHome.com

Website : [Http://www.AntennaHome.com](http://www.AntennaHome.com)