



深圳市兴华鑫电子科技有限公司
Shenzhen xinghuaxin Electronic Technology Co., Ltd

承認書

SPECIFICATION FOR APPROVAL

客戶 (Customer): _____
客戶料號 (Customer P/N): _____
興華鑫型號 (Supplier P/N): HC12095-16 Ω -2048Hz
產品名稱 (Description): 蜂鸣器 (Buzzer)
產品規格 (Specification): 12*9.5MM 无源一体式

客戶承認欄 (Customer Authorization Signature)	深圳市興華鑫電子科技有限公司 承認欄 (Supplier Audit)		
	審核	檢查	制作
	唐国兴	唐玉来	吴银娟
	日期: 2022 年 04 月 19 日 版次: A		

声音让生活更精彩!

地址: 深圳市宝安区新安街道新乐社区新乐路 88 号厂房四层
TEL: 0755-27892904
E-mail: jacky.tang@jsxhxdz.com
Http: www.jsxhxdz.com


深圳市兴华鑫电子科技有限公司

产品规格内容

XHXDZ-HC12095-16Ω-2048Hz

DIMENSIONS Unit:mm

Tolerance:±0.5

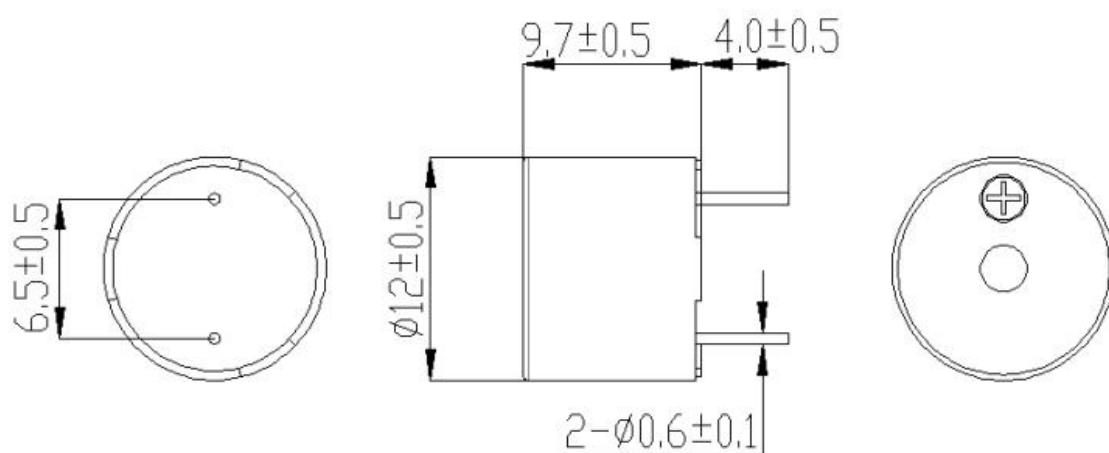

SPECIFICATIONS:

Model NO	HC12095-16Ω-2048Hz
Rated Voltage	3V
Operating Voltage	2.0~5.0V
Rated Current	Max. 50mA
Coil Resistance	$16 \pm 4 \Omega$
sound Pressure level(dB/2048Hz/at 10cm)	Min.90dB
Resonant Frequency	2048Hz
Operating Temperature	-20°C~+70°C
Storage Temperature	-30°C~+80°C


建议过波峰焊的温度：**255+/-5 度**，时间不超过 **3 秒**。

深圳市兴华鑫电子科技有限公司


产品规格内容

Acoustic Characteristics:

The oscillation frequency, current consumption and sound pressure are measured by the measuring instruments shown below

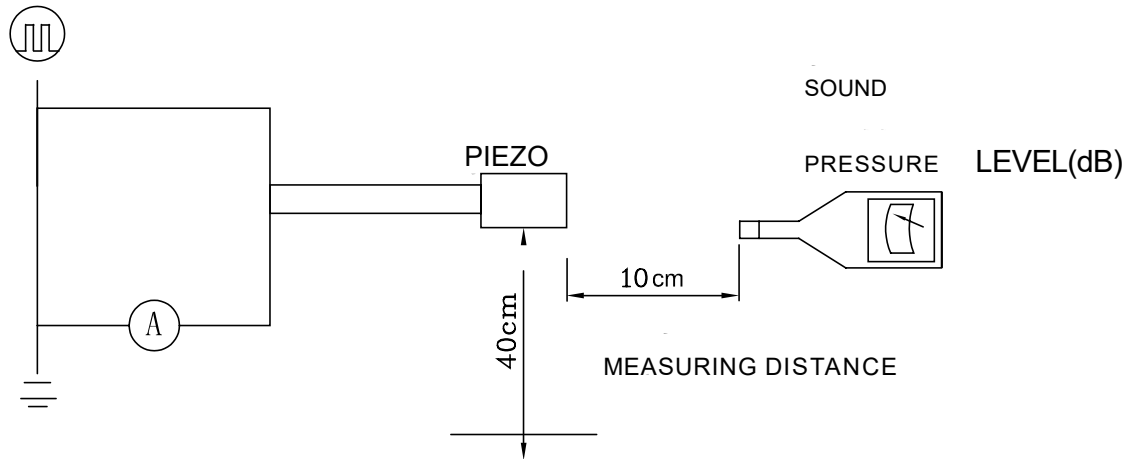

In the measuring test, buzzer is placed as follows:

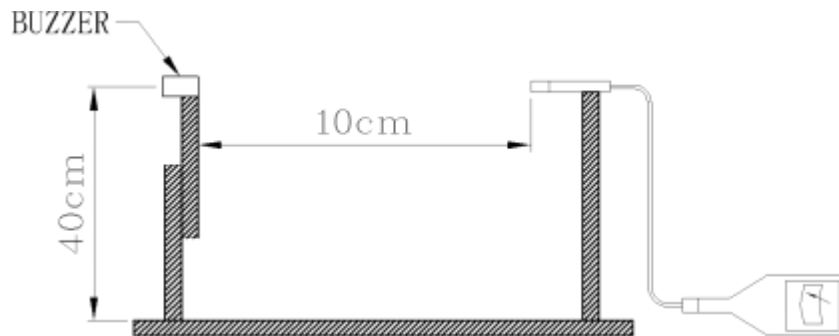

Typical Frequency Response Curve

