



深圳市兴华鑫电子科技有限公司

Shenzhen xinghuaxin Electronic Technology Co., Ltd

承認書

SPECIFICATION FOR APPROVAL

客戶 (Customer):

客戶料號 (Customer P/N):

興華鑫型號 (Supplier P/N):

HC12085-42 Ω -2048Hz-3.7MM

產品名稱 (Description):

蜂鸣器 (Buzzer)

產品規格 (Specification):

12*8.5MM 无源电磁式

客戶承認欄 (Customer Authorization Signature)	深圳市興華鑫電子科技有限公司 承認欄 (Supplier Audit)		
	審核	檢查	制作
	唐国兴	唐玉来	吴银娟
	日期: 2022 年 04 月 19 日 版次: A		

声音让生活更精彩!

地址: 深圳市宝安区新安街道新乐社区新乐路 88 号厂房四层

TEL: 0755-27892904

E-mail: jacky.tang@jsxhxdz.com

Http: www.jsxhxdz.com


深圳市兴华鑫电子科技有限公司

产品规格内容

XHXDZ-HC12085-42Ω-3.7MM

DIMENSIONS Unit:mm

Tolerance:±0.5

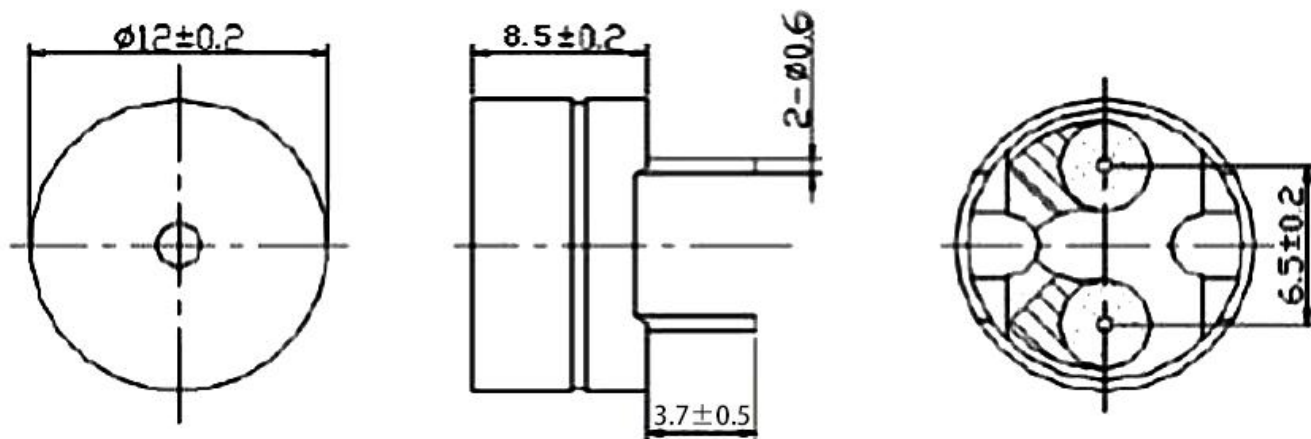

SPECIFICATIONS

Model NO	HC12085-42Ω-3.7MM
Rated Voltage	5V
Operating Voltage	3.0~7.0V
Rated Current	Max. 80mA
Coil Resistance	$42 \pm 4 \Omega$
sound Pressure level(dB/2048Hz/at 10cm)	Min.85dB
Resonant Frequency	2048HZ
Operating Temperature	-20 °C~+60 °C
Storage Temperature	-30 °C~+70 °C


备注： 本产品只适用于手工焊接， 不能过波峰焊。

深圳市兴华鑫电子科技有限公司


产品规格内容

Acoustic Characteristics:

The oscillation frequency, current consumption and sound pressure are measured by the measuring instruments shown below

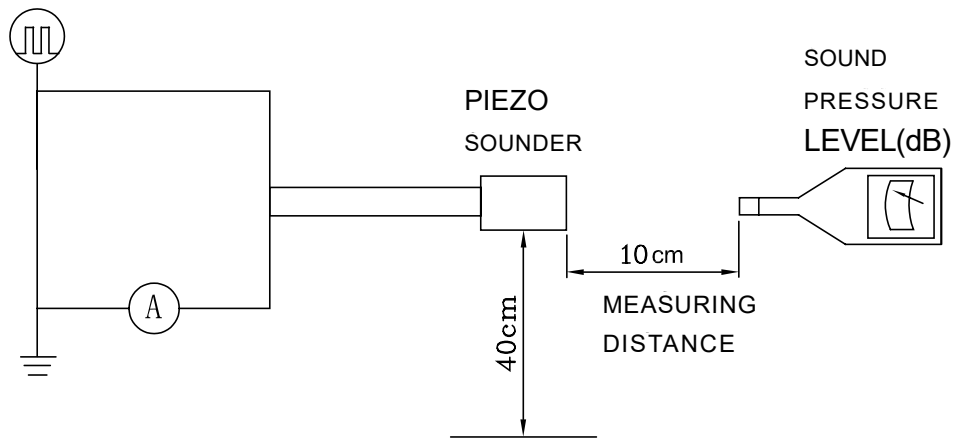

In the measuring test, buzzer is placed as follows:

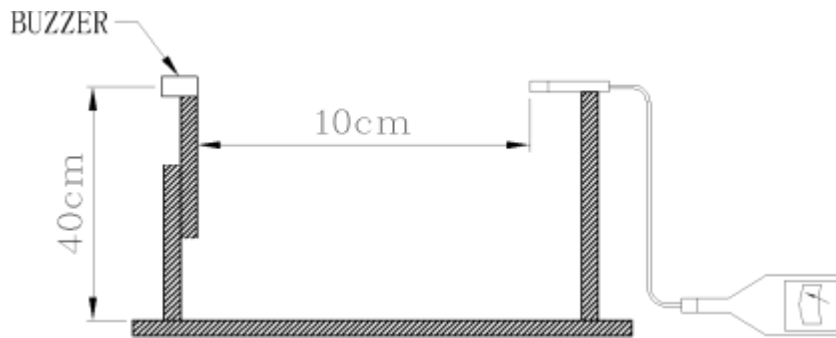

Typical Frequency Response Curve

