
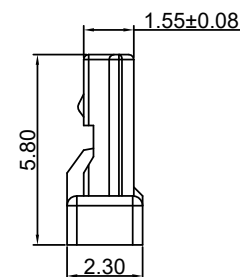
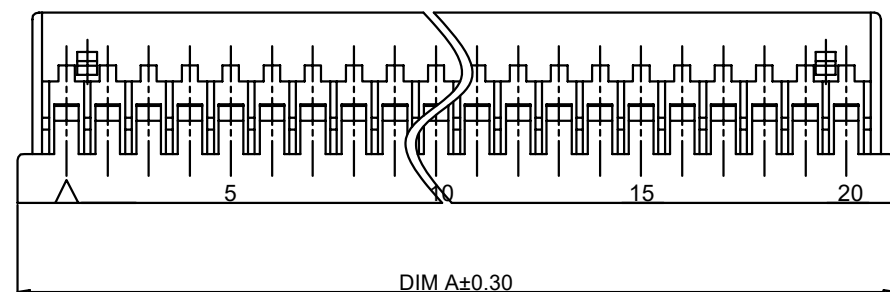


RoHS2.0+REACH

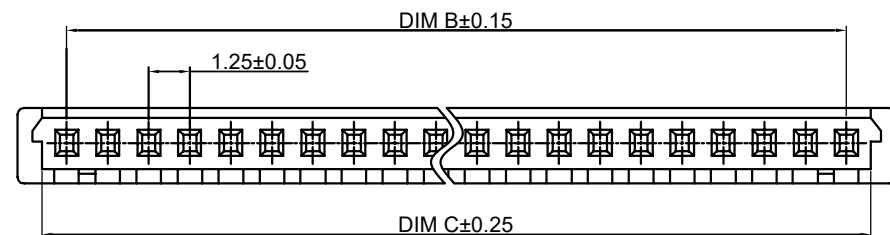

- SPEC.:
- Voltage Rating:150V AC/DC
 - Current Rating:1A AC/DC
 - Withstanding Voltage:500V AC/minute
 - Contact Resistance:20mΩ max
 - Insulation Resistance:500MΩ min
 - Temperature Range:-35°C~+85°C

■Material:

- Insulator:PA66 UL94V-0
- Color:Grey

Poles	Dimensions(mm)		
	A	B	C
02	4.40	1.25	2.90
03	5.65	2.50	4.15
04	6.90	3.75	5.40
05	8.15	5.00	6.65
06	9.40	6.25	7.90
07	10.65	7.50	9.15
08	11.90	8.75	10.40
09	13.15	10.00	11.65
10	14.40	11.25	12.90
11	15.65	12.50	14.15
12	16.90	13.75	15.40
13	18.15	15.00	16.65
14	19.40	16.25	17.90
15	20.65	17.50	19.15
20	26.90	23.75	25.40
25	33.15	30.00	31.65
30	39.40	36.25	37.90

5.0				DRAWING: Frank	GENERAL TOLERANCE .X:=±0.30 .X':=±2° .XX:=±0.25 .XX':=±1° .XXX:=±0.15 .XXX':=±0.5°				
4.0									
3.0				CHECKED: yangjie	UNIT: MM	PROJECTION:	DESCRIPTION: Housing P1.25mm		
2.0									
1.0				APPROVAL:	SCALE: 1:1		PART NO: WF125-20P-002		REV: 1.0
NO.	DATE	DESCRIPTION	DRAWING		SHEET: 1/1		OLD CODE:		SIZE: A4
DRAWING NO:									