
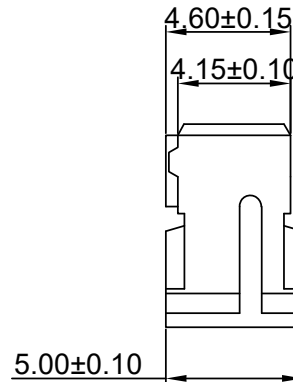
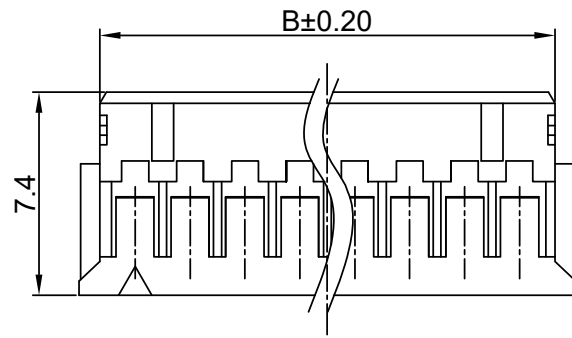


RoHS2.0+REACH

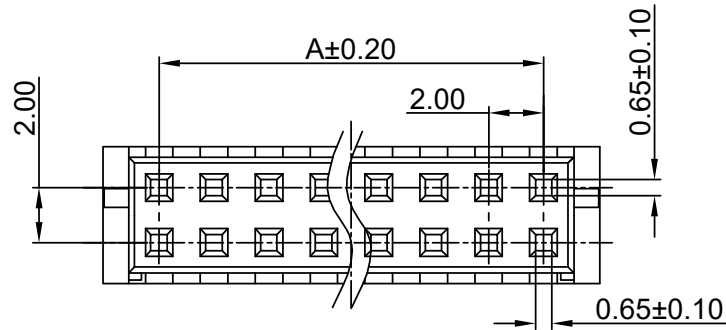

■SPEC.:

- Rated Voltage:250V AC,DC
- Rated Current:3A AC,DC
- Withstand Voltage:800V AC/minute
- Contact Resistance:20mΩ max
- Insulation Resistance:1000MΩ min
- Temperature Range:-25℃~+85℃

■Material:

- Insulator:PA66 UL94V-0
- Color:White

Poles	Dimensions(mm)	
	A	B
2X03	4.00	6.70
2X04	6.00	8.70
2X05	8.00	10.70
2X06	10.00	12.70
2X07	12.00	14.70
2X08	14.00	16.70
2X09	16.00	18.70
2X10	18.00	20.70
2X11	20.00	22.70
2X12	22.00	24.70
2X13	24.00	26.70
2X14	26.00	28.70
2X15	28.00	30.70
2X16	30.00	32.70
2X17	32.00	34.70
2X18	34.00	36.70
2X19	36.00	38.70
2X20	38.00	40.70

5.0			
4.0			
3.0			
2.0			
1.0			
NO.	DATE	DESCRIPTION	DRAWING

DRAWING:
Frank
CHECKED:
yangjie
APPROVAL:

GENERAL TOLERANCE

.X:=±0.30 .X*:=±2°
.XX:=±0.25 .XX*:=±1°
.XXX:=±0.15 .XXX*:=±0.5°

UNIT: MM

PROJECTION:

SCALE: 1:1



SHEET: 1/1

CHIN-BAN
Electronic Technology

DESCRIPTION: Housing P2.00mm

PART NO: **WF200-10P-001**

REV: 1.0

OLD CODE:

DRAWING NO:

SIZE: A4