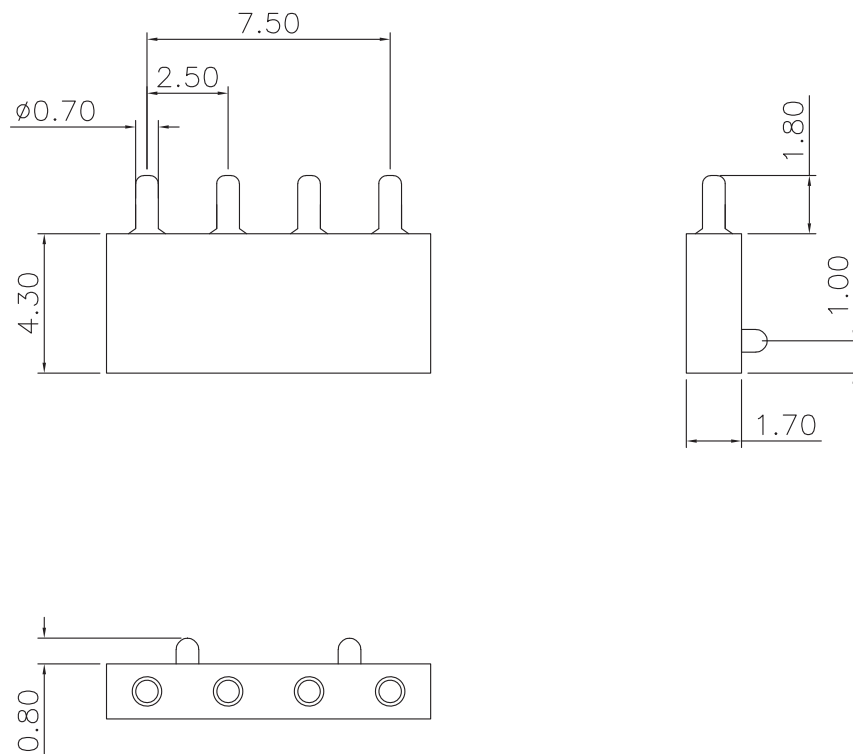

 
 


RoHS



NOTE

- 1.Material
Plunger: Brass C3604
Barrel: Brass C3604
Spring: SUS304
Housing:PA46
- 2.Plating
Plunger: 3 micro-inch minimum Au over 50 micro-inch nickel
Barrel: 3 micro-inch minimum Au over 50 micro-inch nickel
- 3.Electrical
Rated current & voltage: DC 12V; 1.0A Max.
Contact resistance: 50 mohm maximum at normal working height(quiescence)
- 4.Mechanical
Durability: 10,000 cycles(minimum)
- 5.To ensure the best usage,please operate it based on the working height
Based on the engineering drawings,shall not exceed the maximum allowed compression
- 6.To avoid arcing issue, The adaptor start to power supply
after connector mated fully.
- 7.RoHS compliant product.
- 8.SALT SPRAY:24H

5.0				DRAWING: Frank	GENERAL TOLERANCE .X:= ± 0.30 .X*:= $\pm 2^\circ$.XX:= ± 0.20 .XX*:= $\pm 1^\circ$.XXX:= ± 0.10 .XXX*:= $\pm 0.5^\circ$			
4.0								
3.0				CHECKED: yang jie	UNIT: MM	PROJECTION: 	DESCRIPTION: 2.50mm Pitch POGO pin Single Row	
2.0								
1.0				APPROVAL:	SCALE: 1/1		SERIES: PG2501 SERIES	REV: 1.0
REV.	DATE	DESCRIPTION	DRAWING		SHEET: 1/1		PART NO: PG2501-04-005P	SIZE: A4