


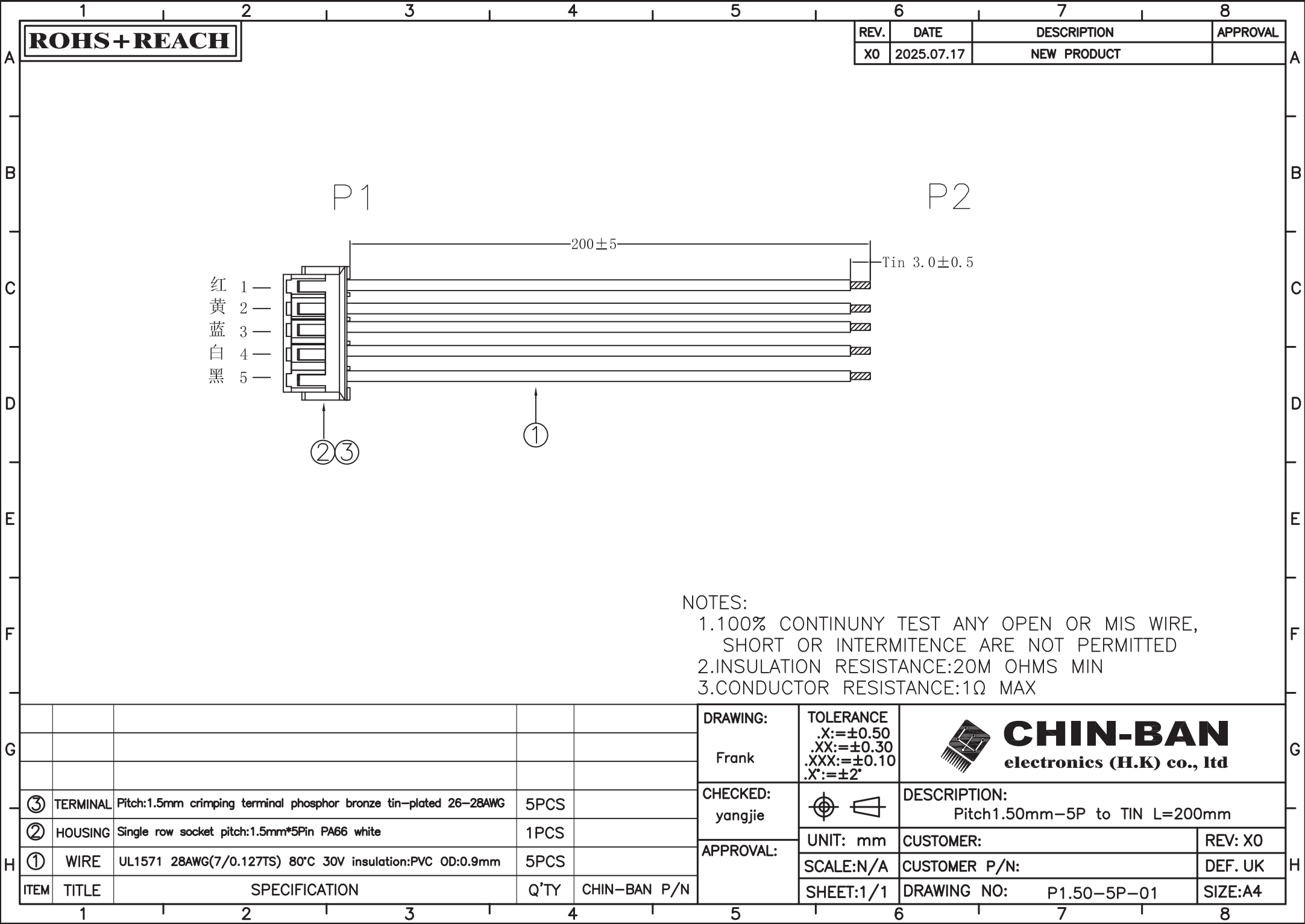

ROHS+REACH

REV.	DATE	DESCRIPTION	APPROVAL
X0	2025.07.17	NEW PRODUCT	

P1

P2

200±5

Tin 3.0±0.5

 
红 1
黄 2
蓝 3
白 4
黑 5

②③

①

NOTES:
1.100% CONTINUNY TEST ANY OPEN OR MIS WIRE,
SHORT OR INTERMITENCE ARE NOT PERMITTED
2.INSULATION RESISTANCE:20M OHMS MIN
3.CONDUCTOR RESISTANCE:1Ω MAX

ITEM	TITLE	SPECIFICATION	Q'TY	CHIN-BAN P/N
③	TERMINAL	Pitch:1.5mm crimping terminal phosphor bronze tin-plated 26-28AWG	5PCS	
②	HOUSING	Single row socket pitch:1.5mm*5Pin PA66 white	1PCS	
①	WIRE	UL1571 28AWG(7/0.127TS) 80°C 30V insulation:PVC OD:0.9mm	5PCS	

DRAWING:	TOLERANCE	 CHIN-BAN electronics (H.K) co., ltd	
Frank	.X:=±0.50 .XX:=±0.30 .XXX:=±0.10 .X*:=±2*		
CHECKED:		DESCRIPTION: Pitch1.50mm-5P to TIN L=200mm	
yangjie			
APPROVAL:	UNIT: mm	CUSTOMER:	REV: X0
	SCALE:N/A	CUSTOMER P/N:	DEF. UK
	SHEET:1/1	DRAWING NO: P1.50-5P-01	SIZE:A4