
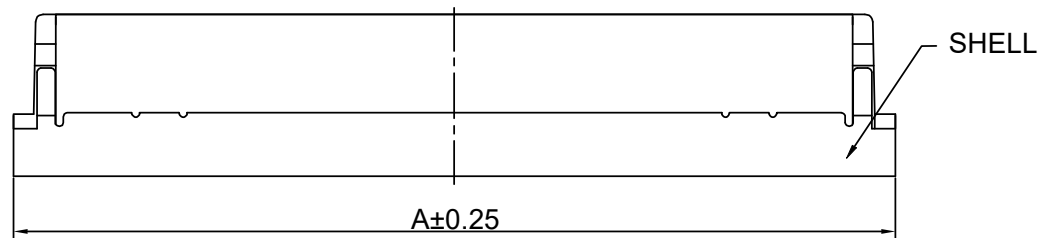
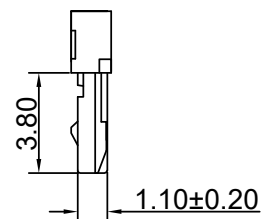


RoHS2.0+REACH

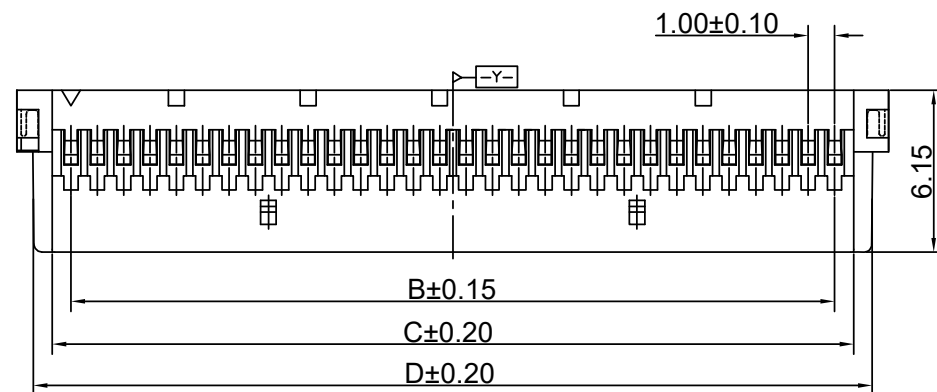

■SPEC.:

- Rated Voltage:100V AC,DC
- Rated Current:1A AC,DC
- Withstand Voltage:300V AC/minute
- Contact Resistance:30mΩ max
- Insulation Resistance:500MΩ min
- Temperature Range:-35℃~+85℃

■Material:

- Insulator:PA66 UL94V-0
Color :Natural
- Shell:Stainless Steel

Poles	Dimensions(mm)			
	A	B	C	D
14	17.50	13.00	14.44	15.90
20	23.50	19.00	20.44	21.90
30	33.50	29.00	30.44	31.90

5.0				DRAWING:	GENERAL TOLERANCE .X:=±0.30 .X*:=±2° .XX:=±0.25 .XX*:=±1° .XXX:=±0.15 .XXX*:=±0.5°		CHIN-BAN Electronic Technology	
4.0				Frank				
3.0				CHECKED:	UNIT: MM	PROJECTION:	DESCRIPTION: Housing P1.00mm	
2.0				yangjie				
1.0				APPROVAL:	SCALE: 1:1		PART NO: WF100-20P-001	REV: 1.0
NO.	DATE	DESCRIPTION	DRAWING		SHEET: 1/1		OLD CODE:	SIZE: A4