


YX-A11-R430880-RT0870



APPLICATIONS

- Cross outlet
- Coil attached square diskette,size:42.5m
- Double-sided magnetic tape
- Attach the coil to double-sided tape
- Double line tinning

SHAPE & DIMENSIONS

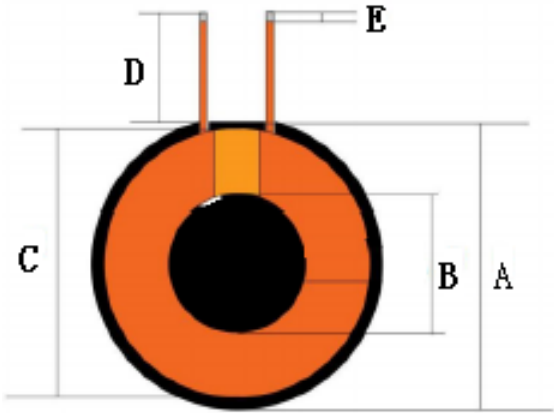

A	42.5Max
B	20.5±0.5
C	39.2±0.5
D	70±2
E	3.0±1

中间加贴20*1.5磁片

AIR COIL SPECIFICATIONS

Number of Coils	Wire Diameters	Turns Ratio
1	ø:0.08*80P	11TS

MAXIMUM RATINGS

Operating Temperature / Humidity	Storage Temperature / Humidity
-40 to +85°C / 10 to 65% R.H.	-25 to +125°C / 10 to 65% R.H.

ELECTRICAL CHARACTERISTICS

OCL [100kHz 0.1V] (μH)	DCR [100kHz 0.1V] (mΩ)	WPC Compliant
8.3± 5%	70max.	Yes

PACKAGING : BOX TYPE

Dimensions (mm)	Quantity (pcs)
Tray	Qty per tray
Small carton	Qty per small carton
Outer carton	Qty per outer carton

OTHERS

Weight (g) typ.
32.90