



YX-A11-R430824-RT0845



APPLICATIONS

- Cross outlet
- Coil attached square diskette,size:43mm
- Double-sided magnetic tape
- Attach the coil to double-sided tape
- Double line tinning

SHAPE & DIMENSIONS

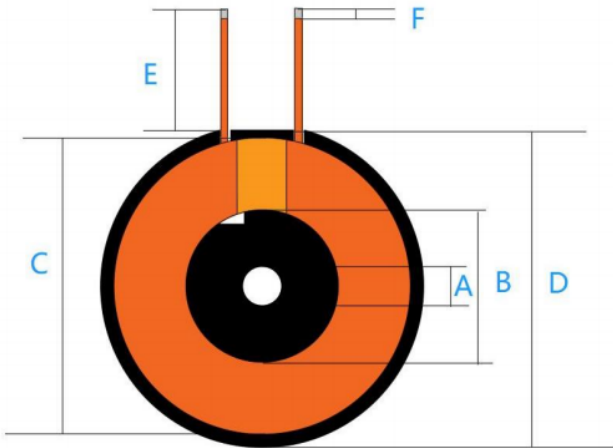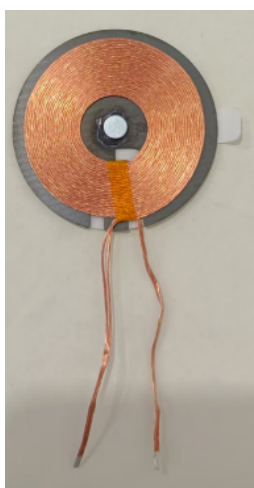

A	5*1.5磁铁
B	14.0±2.0
C	38±2
D	43±2
E	45±2
F	3.0±1

AIR COIL SPECIFICATIONS

Number of Coils	Wire Diameters	Turns Ratio
1	ø:0.08*24*2P	12TS

MAXIMUM RATINGS

Operating Temperature / Humidity	Storage Temperature / Humidity
-40 to +85°C / 10 to 65% R.H.	-25 to +125°C / 10 to 65% R.H.

ELECTRICAL CHARACTERISTICS

OCL [100kHz 0.1V] (μH)	DCR [100kHz 0.1V] (mΩ)	WPC Compliant
6.80 ± 10%	70max.	Yes

PACKAGING : BOX TYPE

Dimensions (mm)		Quantity (pcs)	
Tray	—	Qty per tray	—
Small carton	320x320x55	Qty per small carton	6
Outer carton	350x350x180	Qty per outer carton	300

OTHERS

Weight (g) typ.
32.90

A:正装5*1.5磁铁（2800GS）