

RoHS

SPECIFICATIONS

Rated Current:1.5AMP

Contact Resistance:20mΩ Max

Withstand Voltage:500V AC/DC

Insulation Resistance:1000MΩ Min

Operation Temperature:−40℃ to +105℃



Contact Material:Brass

Contact Plating:Au Over Ni



Insulator Material:Polyester(UL94V−0)

Standard: PA6T

Max.Processing Temp: 230℃ for 30−60 seconds
(260℃ for 5 seconds)

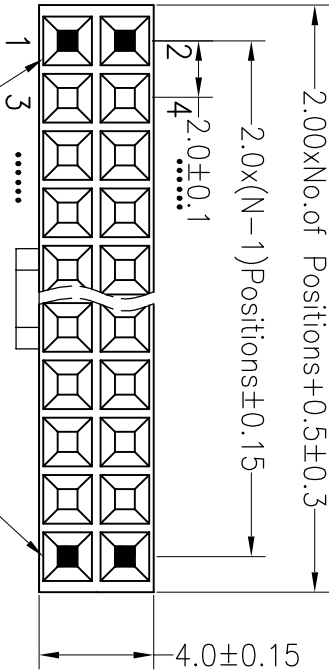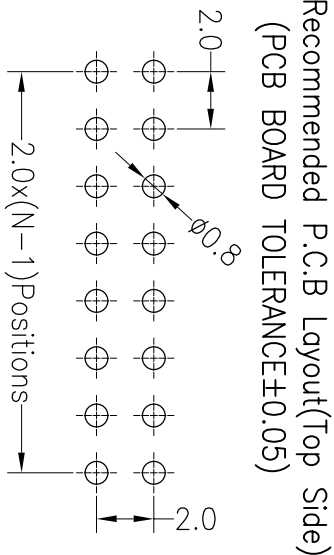

头尾各空2P

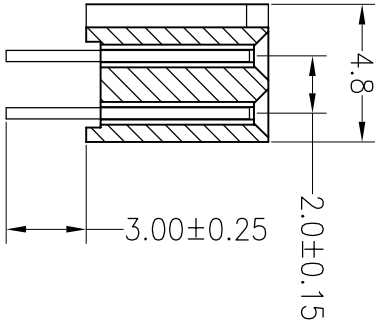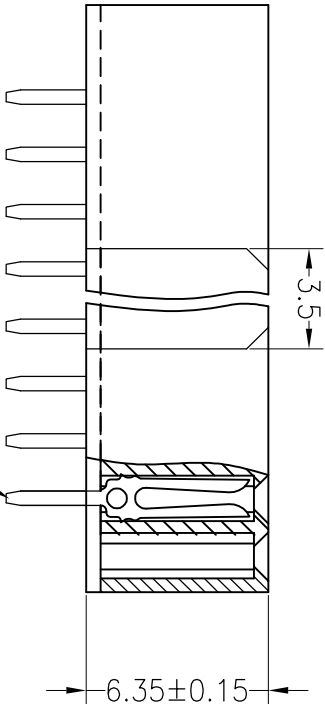

深圳市连盛精密连接器有限公司

PART NO.

1020200046

TITLE:

2.0FH H=6.35 2X20P 头尾各空2P DIP
PC3.0 AU1U PA6T 带全凸