

Insulator: Black glass filled polyester PPS-GF30-FR

Black glass filled polyester PPS-GF30-FR

UL 94V-0

Sleeve: Brass

Contact clip(4/6 finger): Beryllium copper(C17200)

Accepted pin: Ø0.38 to 0.56mm

Forces: (polished steel gauge Ø0.43mm)

--Insertion 2 N typ

1 N typ

Mechanical life: min500 cycles


3A

Contact resistance: max 10mΩ

Dielectric resistance: Min 1000M Ω

Operating temperature: -40°C to +105°C

Soldering temperature: 260°C, 10s max

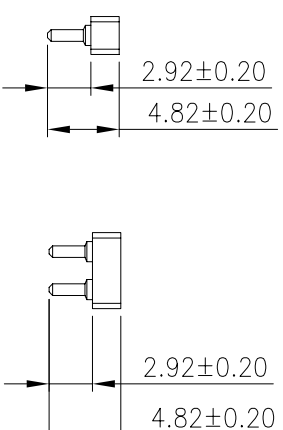

0306

深圳市连盛精密连接器有限公司									
PART NO.		1020300174							
TITLE:		2.54X1.9圆孔排母 1x3p							
PROJ.									
SHEET	1/1								
SIZE	A4								
UNIT	mm								
SCALE	FIT								
		DRAW		YTYuSheng		12.08.08			
OPERATION		X.X		±0.30					
		X.XX		±0.20		CHECK			
		X.XXX		±0.10					
Angle		±3°		APPROVE					
DIM		TOL							
CHANGE									
MODIFICATION DESCRIPTION									
DATE									
REV									