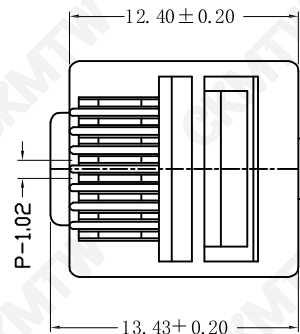


特征:

1、电气特性:

A:额定电压:250V AC.

B:额定电流:2A

C:耐电压测试:1000V DC/1分钟, 电流小于0.5A

D:绝缘抗阻: 大于500M 欧姆, 1000VDC/1分钟

F:接触抗阻:不大于20mΩ (毫欧姆)

2、机械特性:

A:拉力测试-电缆至插座张力强度至少20磅 (89N)

B:耐力测试-插拔测试500次以上

3、使用温度范围:-40℃~+85℃

4、环保符合性:

产品符合ROHS, REACH等环保规格.

☐ 屏蔽壳 Shield	☐ 黄铜 Brass	☐ 铁 Spec	1
Au: ☐ G/F ☐ 1u" ☐ 3u" ☐ Ni ☐ 80u"			
胶壳 PC(聚碳酸酯)	☐ 94-V0 ☒ 94-V2		1
金片 (PIN针) Contacts	☒ 黄铜 Brass	☐ 磷铜 Phosphor copper	8
☐ G/F ☐ 1u" ☐ 3u" ☐ 6u" ☐ 15u" ☐ 30u" ☐ 50u" ☐ OTHER			

BLADE:	202	304	309	311	314	319	
Drawing							
Mark							
BLADE:	203/204	209/210	307/308	312/313			
Drawing							
Mark							

TOLERANCE TABLE	
.0	±0.30
.00	±0.20
.000	±0.05

APPROVED:	DATE:	Ckmtw 深圳市灿科盟实业有限公司 CHANKLEMENT INDUSTRYCO., LTD			
CHECKED:	DATE:	TITLE: 水晶头 CAT5 RJ45-8P/8C 公头 短体 圆孔			
DRAWN: L. YUN	DATE: 2020-11-17	PART. NO.	R-RJ45T08P-M004		
		UNIT	mm	SCALE	free
		FILE NO.	Ckmtw-RJ45-0314	REV.	A HY04