
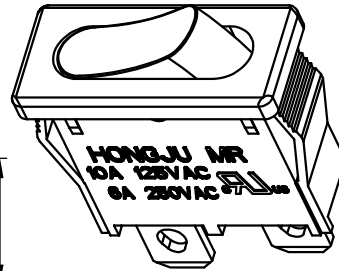


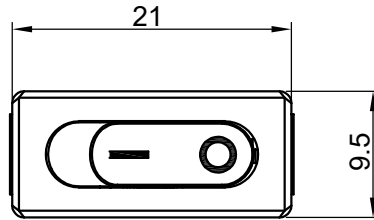

MR-2

Rating: 10A 125V AC (UL CUL) 6A 250V AC (UL CUL TUV CB) 



Contact Resistance: 50mΩ Max

Insulation Resistance: DC 500V 100MΩ Min


Dielectric Strength: AC1500V 1 minute

Electrical life: 10,000 cycles

Operating Temperature: 0°C ~85°C

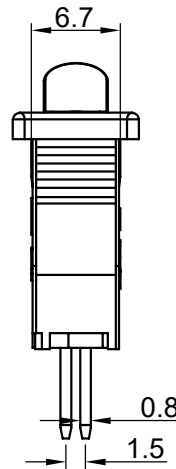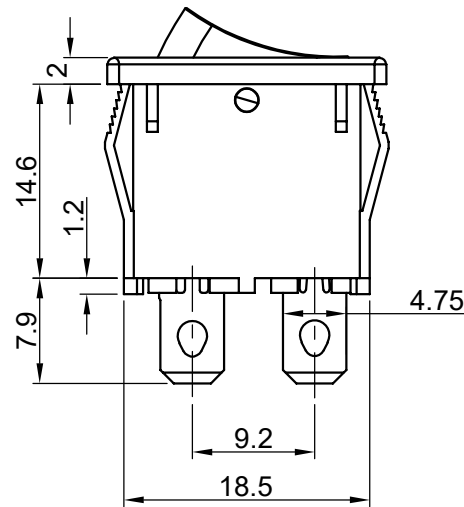


CUT-OUT

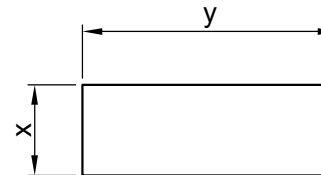

	X	Y
0.75~1.25	6.8-0.1	19.2±0.1
1.25~2.00	6.8-0.1	19.2±0.1
2.00~3.00	6.8-0.1	19.2±0.1

 SWITCHING CIRCUIT



MATERIAL:

Body:Nylon66,UL rated:94V-2 min

Actuator:Nylon66,UL rated:94V-2 min

Terminal:Brass,silver or tin plated

X	0	1	5	9	A	C
Marking	None	•	! ○	○ !	! •	■

				公差 TOLERANCES		.X± 0.3 .XX± 0.15		角度 ANGLE± 1°		单位 DIMENSION UNIT mm.	
				版本 VERSION	A1	比例尺 SCALE	NONE	日期 DATE	2020.07.15	品名 TITLE	图号 DRAWING NO
				核准		核对	Z. H. B.	绘图		MR2-110-C5N-BB	MR2-110-C5N-BB_A1
版本 VER	变更说明 CHANGE DESCRIPTION	日期 DATE	ECN NO.	APPROVED BY		CHECKED BY		DRAWN BY			