


22. 20

- 1.Current Rating:7A AC, DC
- 2.Voltage Rating:600V AC, DC
- 3.Temperatuer Range: $-25^{\circ}\text{C}\sim+85^{\circ}\text{C}$
- 4.Contact Resistance:20m Ω Max
- 5.Insulation Resistance: 1000M Ω Min
- 6.Withstanding Voltang: 1500V AC/minute
- 7.Material: Wafer Nylon66
PIN Brass Tin-plated

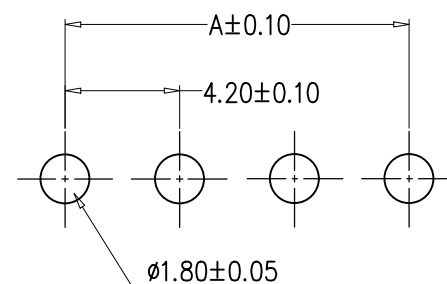