


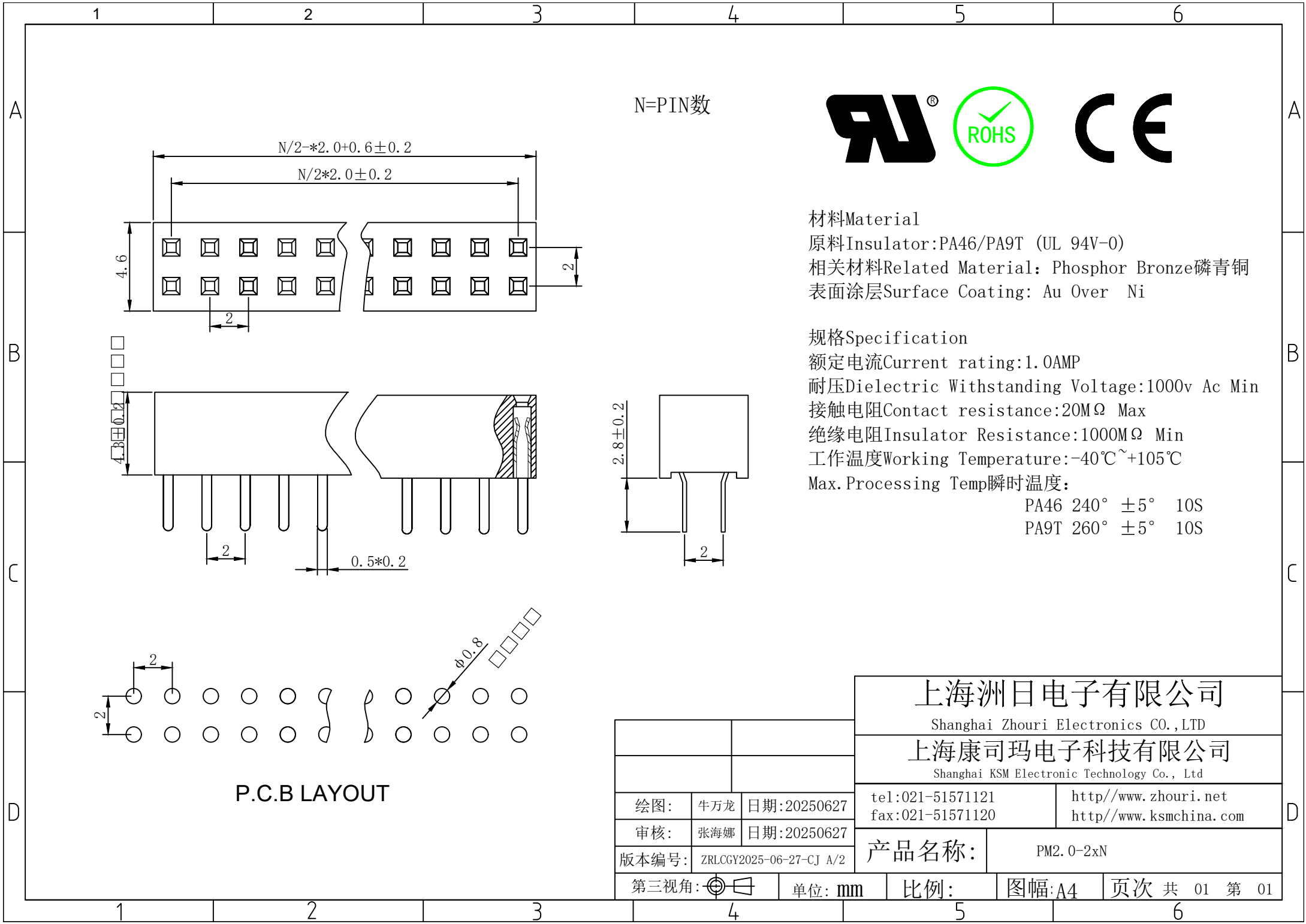

N=PIN数



材料Material
原料Insulator:PA46/PA9T (UL 94V-0)
相关材料Related Material: Phosphor Bronze磷青铜
表面涂层Surface Coating: Au Over Ni

规格Specification
额定电流Current rating:1.0AMP
耐压Dielectric Withstanding Voltage:1000v Ac Min
接触电阻Contact resistance:20M Ω Max
绝缘电阻Insulator Resistance:1000M Ω Min
工作温度Working Temperature:-40 $^{\circ}$ C~+105 $^{\circ}$ C
Max.Processing Temp瞬时温度:
PA46 240 $^{\circ}$ $\pm 5^{\circ}$ 10S
PA9T 260 $^{\circ}$ $\pm 5^{\circ}$ 10S

上海洲日电子有限公司			
Shanghai Zhouri Electronics CO.,LTD			
上海康司玛电子科技有限公司			
Shanghai KSM Electronic Technology Co., Ltd			
tel:021-51571121		http://www.zhouri.net	
fax:021-51571120		http://www.ksmchina.com	
产品名称:		PM2.0-2xN	
第三视角:		单位: mm	比例: 图幅:A4 页次 共 01 第 01