
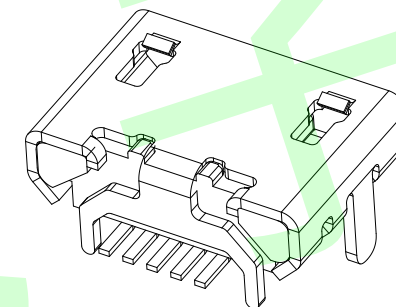
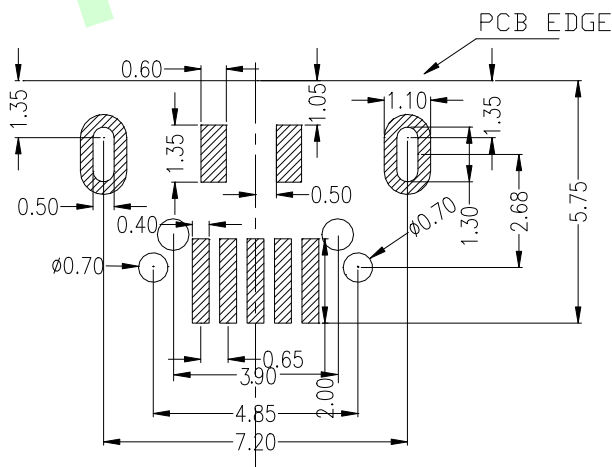
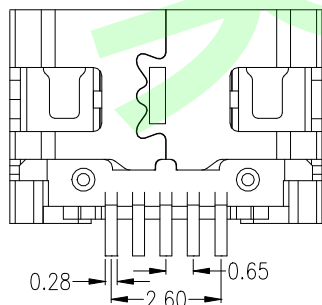
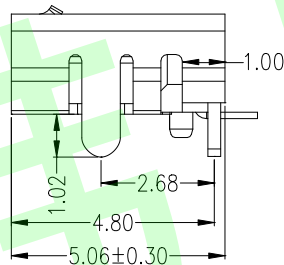
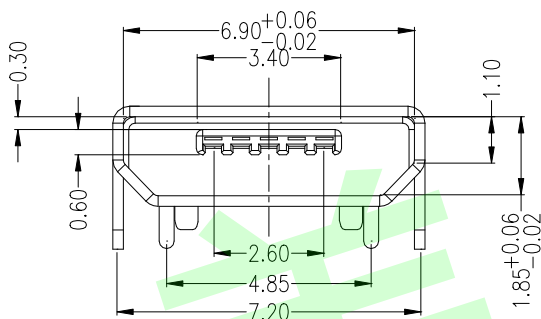
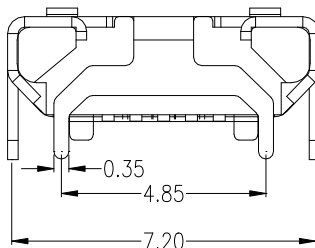


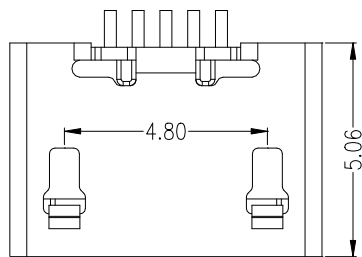

Note:

1.Material:

- 1.1 Housing: High temperature thermoplastic with g.f,UL94v-0
- 1.2 Contact: copper alloy,t=0.15mm
- 1.3 Shell: copper alloy,t=0.25mm

2.Specification:

- 2.1 Current rating: 1 A Max.
- 2.2 Dielectric withstanding voltage: 100 V(ac) for 1 min.
- 2.3 Contact resistance: 50 mW Max.
- 2.4 Insulation resistance: 100 MW Min.
- 2.5 Total mating force: 3.57 Kgf Max.
- 2.6 Total unmating force: 1.0 Kgf Min.0.81~2.05 Kgf Min.after 10000 insertion/extraction cycles
- 2.7 Temperature range: -30°C~80°C

东莞市美韩电子科技有限公司

Dongguan Usakro Electronic Technology Co., Ltd.

一般公差

XX. ±	XXX. ±
.X ±0.25	.XXX ±
.XX ±0.15	X.* ± 3°
.XXX ±0.05	.X.* ± 0.5°

比例 SCALE	N/A
单位 UNIT	MM
尺寸 SIZE	A4

绘图 DRAWIN	W-J-C
审核 CHECKED	
核准 APPROVE	

日期 DATE	2013.08.01
日期 DATE	
日期 DATE	

图号 DRW NO:	MICRO NJ5P-1.0-1.25
TITLE	
MIRCO USB 5S 4.85牛角有柱平口针加长0.70	

版次 REV.	1.0
页次 PAGE	1/1