
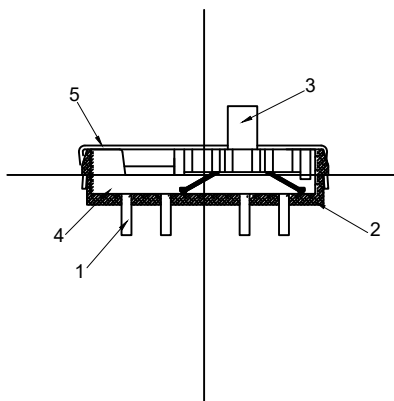
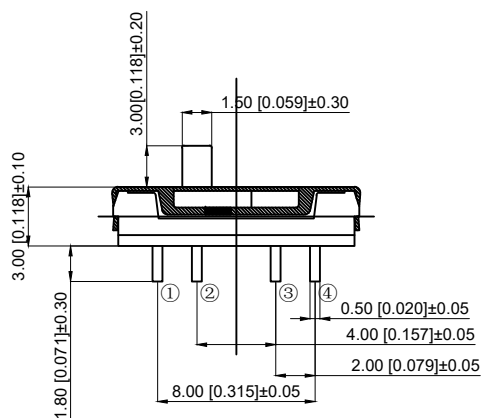
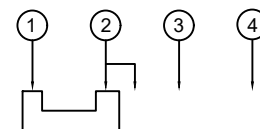
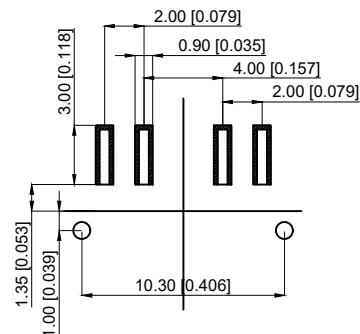
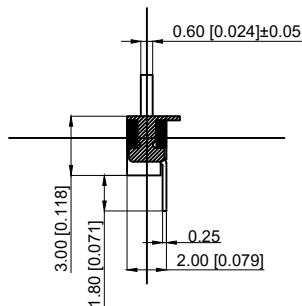


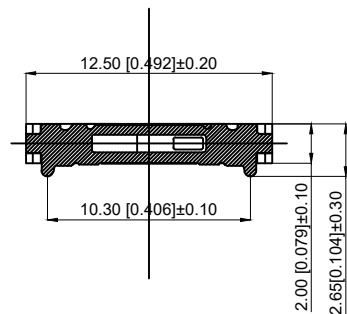

Product specification:

产品规格:

Rated range: 50mA DC12V

额定范围: 50mA DC12V

Insulation resistance: 100m Ω min

绝缘电阻: 100mΩ min

Withstand voltage strength: AC100V

耐压强度: AC100V

Mechanical life: 10000 cycles

机械寿命: 10000 cycles

Operating temperature: - 10 °C to +60 °C

操作温度: -10°C to +60°C

Operating force: 200 ± 80gf

操作力: 200±80gf

Material property: SGS

材料属性: SGS

5	Upper lid 上盖	SUS	1	silvery white 银白色
4	Contact reed 接触簧片	Phosphor bronze 磷青铜	1	Ag plating 镀银
3	Handle 手柄	PA46	1	black 黑色
2	Base 底座	LCP	1	black 黑色
1	Card 卡件	Brass 黄铜	1	Ag plating 镀银
NO 序号	Part name 部件名	Material 材料	QTY 数量	Remark 备注

A4				
A3				
A2				
A1				
REV	DATE	REVISION	DESCRIPTION	ISSUE



COMMON TOLERANCE

X.XX	± 0.10
X.X	± 0.15
X	± 0.25
ANGULAR	—

UNIT	MM	PROJECTED		PRODUCT NAME:
DRAWN BY	FUYUAN	CHECKED BY	COCO	MODEL NO: TP608221330
DATE	2019	APPROVAL B	ALEN	Https: www.rocpcu.tw
ROCPCU TECHNOLOGY CO.,LTD				
Copies are issued in strict confidence and shall not be reproduced or copied, or used as the basic of manufacture or sale of apparatus without permission				