


KU SERIES

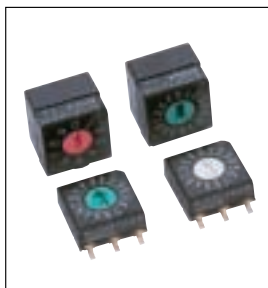


LOW PROFILE ROTARY DIP SWITCHES

Lead-free Type


FEATURES

- Low profile of 7mm square and 3mm high provides to increase a capacity of surface mounting P.C.B.
- Beryllium copper of spring using and high grade stainless steel are used, and gained a fine click touch of stepping.
- Terminal pitch is 0.1 inch as same as series K.
- By employing an engineering plastic, heat resisting is much improved.
- Horizontal(H) type is newly available(7mm square and 6mm high).
- SMT units are compatible with an automatic assembling equipment, reflow mounting and washable. (Compatible with automatic handling methods; such as a tape and stick).

HOW TO ORDER

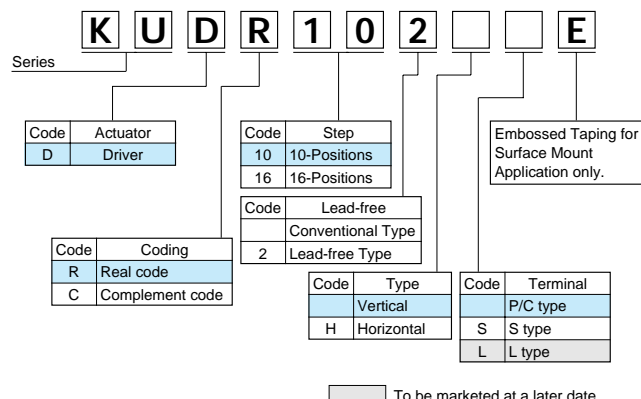

KH SERIES

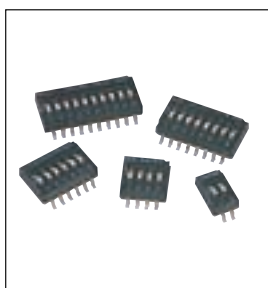


HALF PITCH DIP SWITCHES

FEATURES

- These super-miniature (a terminal pitch of 0.05 inch) multi-contact switches are designed for use inside a very space saving and high technical electronic equipment.
- Reliability maintained with a size reduction of 41.9% (compared with our 8 poles standard DIP switches).
- The plastic case is designed for better heat resistance.
- Gold-plated electrical contacts are the standard specification.
- SMT units are compatible with an automatic assembling equipment, reflow (tape sealing) mounting and washable. (Compatible with automatic handling methods; such as a tape and stick).


300mil SOP Standard

HOW TO ORDER

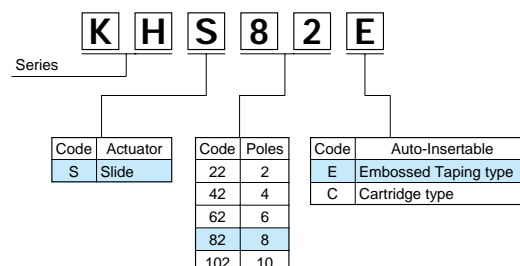

* The 4 pole version only is also available with the **1.7mm height** as KHU04 super low profile dip switch.

KHU 04

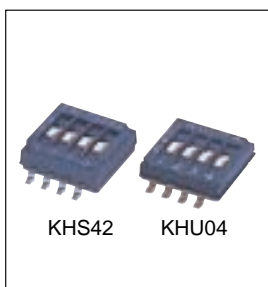

SUPER LOW PROFILE DIP SWITCH

Lead-free Type

FEATURES

- These super-miniature (a terminal pitch of 0.05 inch) multi-contact switches are designed for use inside a very space saving and high technical electronic equipment.
- Reliability maintained with a size reduction of 41.9% (compared with our 8 poles standard DIP switches).
- The plastic case is designed for better heat resistance.
- Gold-plated electrical contacts are the standard specification.
- SMT units are compatible with an automatic assembling equipment, reflow (tape sealing) mounting and washable. (Compatible with automatic handling methods; such as a tape and stick).

300mil SOP Standard

DIMENSION

