
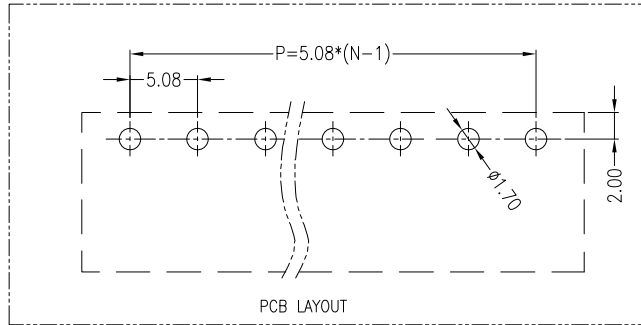
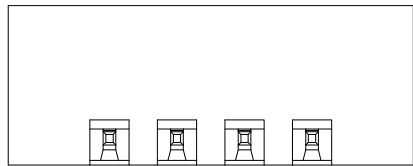
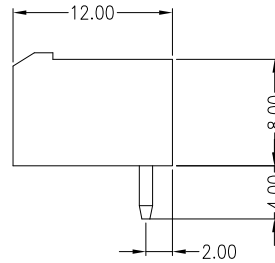


公差参数:

Poles	Dim	Dim P	Dim L
2-6P		±0.10	±0.20
7-12P		±0.20	±0.30
13-18P		±0.25	±0.40
19-24P		±0.30	±0.50

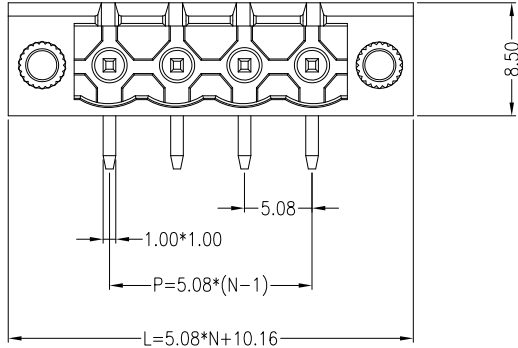

材料及电镀

①. 塑件主体: PA66, UL94V-0

②. 焊 针: 黄铜, 镀镍

电气性能

额定电压: 300V

额定电流: 15A

接触电阻: 20mΩ (Max)

绝缘电阻: 500MΩ \DC500V

耐 电 压: AC2000V\1Min

机械性能

温度范围: -40℃ ~ +105℃

瞬时温度: +250℃ , 5秒

Ordering Information

HC2EDG	*	*	*	-	NP	-	*
Type		插拔式接口					
2.54=2.54mm		3.81=3.81mm					
5.08=5.08mm		7.62=7.62mm					
No. of Pins		2-24Pin					
2P=2Pin		3P=3Pin					
Colour		Y=Green					
L=Blue		O=Orange					
R=Red		B=Black					
GR=Gray							

			GENREL TOLERANCE	制 图 DRAWING	07	深圳市华灿天禄电子有限公司 ShenzhenhuacantianluELECTRONICS CO.,LTD			
			DIM TOL	审 核 CHECK					
			X.X ±0.50	批 准 APPROVAL		产品名称 TITLE	5.08 单排 插拔式 接线端子 带螺丝 弯针	版 本 REV.	A
1	初版发行		X.XX ±0.30	比 例 SCALE		产品料号 PART NO.	HC2EDGRM-5.08-NP-X	单 位 UNITS	mm
			X.XXX ±0.10	投 影 Projection		材 料 MATERIAL		页 次 SHEET	1/1
			Angle ±3.0°						