

Rohs

SPECIFICATIONS

Rated Current:3.0AMP

Contact Resistance: 20m Ω Max

Withstand Voltage: 1000V AC/DC

Insulation Resistance: 1000M Ω Min

Operation Temperature: -40°C to $+105^{\circ}\text{C}$

Contact Material: Brass



Contact Plating: Au or Sn Over Ni

Insulator Material: Polyester (UL94V-0)

Standard: PA6T

Max. Processing Temp: 230°C for 30–60 seconds

(260°C for 5 seconds)

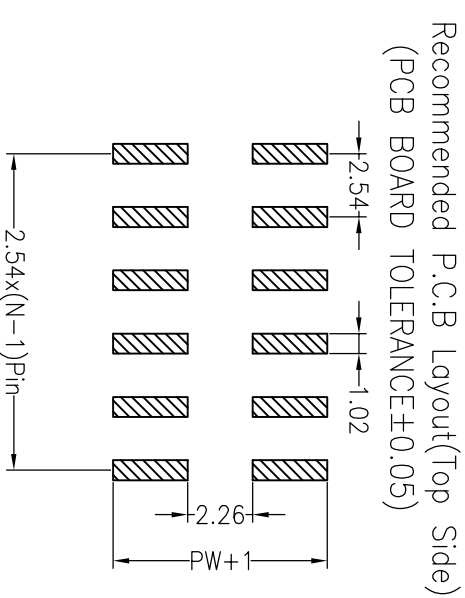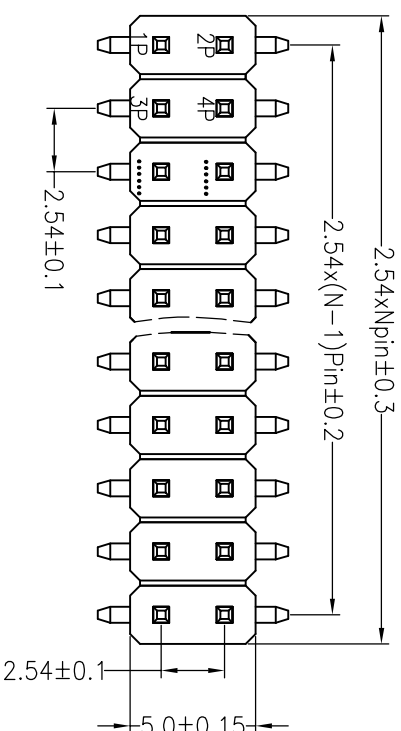

Ordering Information

P X X X XX X X XX X XXXX

[illegible]

Dimension antitheses list								
ITEM	PA	PB	PW	L1	L2	L3	H	W
001	6.00	3.20	7.50	11.00			2.5	5.0
Alternate								

深圳市连盛精密连接器有限公司											
					OPERATION		DRAW			SCALE	FIT
					X.X	±0.30				UNIT	mm
					X.XX	±0.20	CHECK			SIZE	A4
					X.XXX	±0.10				SHEET	1/1
A0	2012.04.11		NEW DRAWING		Angle	±3°	APPROVE			TITLE: 2.54PH H=2.5 2XNP SMT=7.5 PA6 PB3.2 L=11.0 AU0.6U PA6T	
REV	DATE	MODIFICATION	DESCRIPTION	CHANGE	DIM	TOL				PROJ.	☎