

Rohs

SPECIFICATIONS

Rated Current:3.0AMP

Contact Resistance: 20m Ω Max

Withstand Voltage:1000V AC/DC

Insulation Resistance:1000M Ω Min

Operation Temperature: -40°C to $+105^{\circ}\text{C}$

Contact Material:Brass


Contact Plating: Au or Sn Over Ni

Insulator Material: Polyester (UL94V-0)


Standard: PA6T

Max. Processing Temp: 230°C for 30–60 seconds

(260°C for 5 seconds)

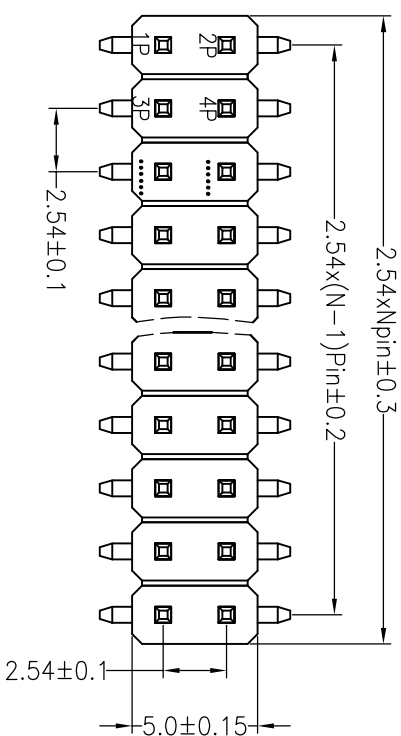

Recommended P.C.B Layout(Top Side)
(PCB BOARD TOLERANCE $\pm$ 0.05)


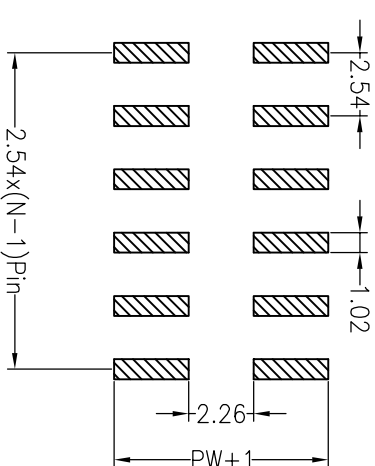


Ordering Information

P X X X XX X X XX X XXXX

产品类别	产品规格	厚度	材料	单位	产品形态	原料	重量	包装方式
P-材料	1=27 2=20 3=24 4=36 5=10 A=127±2.54	1=单 2=双 3=三 4=四	1=40P	1=IP 2=PA 3=MT 4=SH 5=树脂	1=BT 2=LLP 01=0 3=PPS 4=PA46 05=30	0=玻璃 1=陶瓷 2=金属 3=塑料 4=纤维 5=合金	1=管 2=板 3=带 4=盘 5=盒	

Dimension on/tresses list								
ITEM	PA	PB	PW	L1	L2	L3	H	W
001	6.00	3.20	7.50	11.00			2.5	5.0
Alternate								

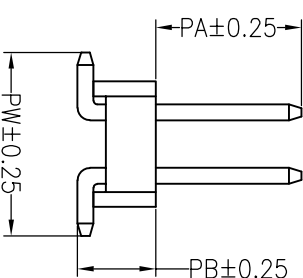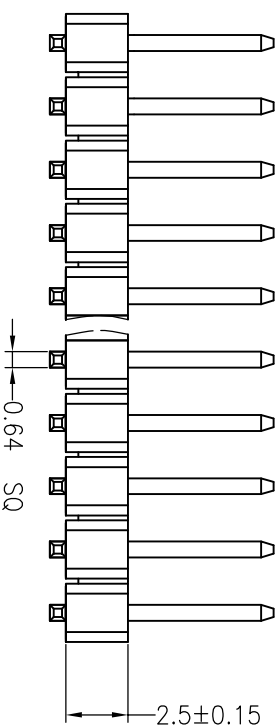

深圳市连盛精密连接器有限公司

RT NO.	1010301734
--------	------------

2.54PH H=2.5 2XNP SMT=7.5 PA6.0

PB3.2 L=11.0 AU0.6U PA6T