
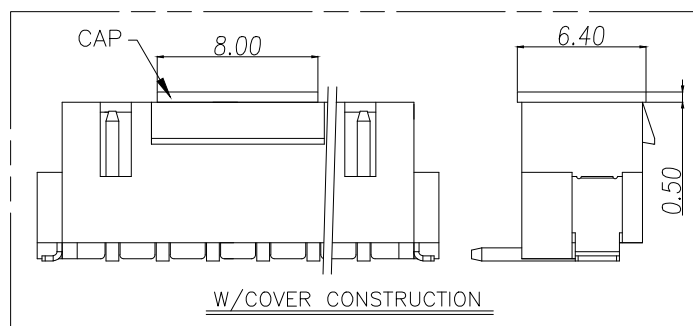
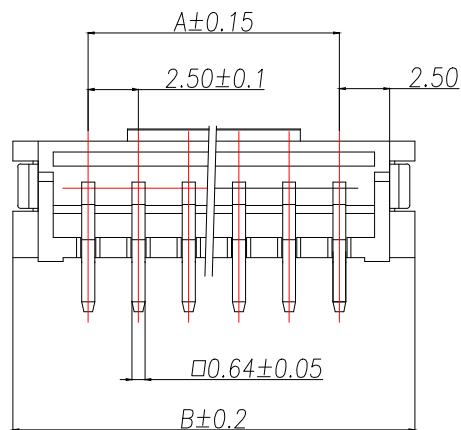
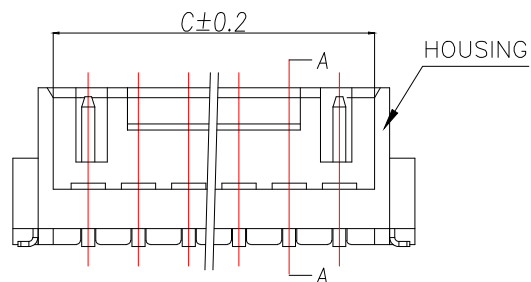


序号	名称	数量
1	基座	1
2	阳接触针	n
3	焊片	2

说明:

1. 产品表面清洁,无锈蚀、氧化、裂纹、缺芯、毛刺、及其它机械损伤;
2. 塑胶材料:LCP UL94V-0,颜色:本色;
3. 焊片:黄铜,镍底30u"Min.,镀锡50u"Min.;
4. 接触针:黄铜,镍底30u"Min.,镀锡50u"Min.;
5. 满足灼热丝温度850度.
6. 工作温度-40~+85°C
7. 额定电流:3A AC/DC
8. 额定电压:250V AC/DC
9. 接触阻抗:10mΩ Max.
10. 绝缘阻抗:1000MΩ Min.
11. 耐电压:1000V AC FOR 1 MINUTE

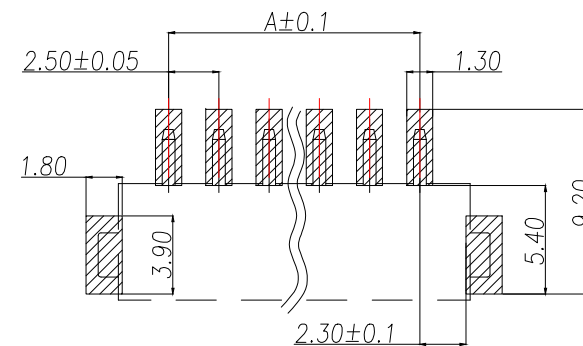

PCB LAYOUT
TOL.: ± 0.05

P/N	PIN	DIM A	DIM B	DIM C
ZX-HA2.54-2PLT-XM	2	2.50	9.90	5.90
ZX-HA2.54-3PLT-XM	3	5.00	12.40	8.40
ZX-HA2.54-4PLT-XM	4	7.50	14.90	10.90
ZX-HA2.54-5PLT-XM	5	10.00	17.40	13.40
ZX-HA2.54-6PLT-XM	6	12.50	19.90	15.90
ZX-HA2.54-7PLT-XM	7	15.00	22.40	18.40
ZX-HA2.54-8PLT-XM	8	17.50	24.90	20.90
ZX-HA2.54-9PLT-XM	9	20.00	27.40	23.40
ZX-HA2.54-10PLT-XM	10	22.50	29.90	25.90
ZX-HA2.54-11PLT-XM	11	25.00	32.40	28.40
ZX-HA2.54-12PLT-XM	12	27.50	34.90	30.90
ZX-HA2.54-13PLT-XM	13	30.00	37.40	33.40
ZX-HA2.54-14PLT-XM	14	32.50	39.90	35.90
ZX-HA2.54-15PLT-XM	15	35.00	42.40	38.40
ZX-HA2.54-16PLT-XM	16	37.50	44.90	40.90
ZX-HA2.54-17PLT-XM	17	40.00	47.40	43.40
ZX-HA2.54-18PLT-XM	18	42.50	49.90	45.90
ZX-HA2.54-19PLT-XM	19	45.00	52.40	48.40
ZX-HA2.54-20PLT-XM	20	47.50	54.90	50.90

制图 DRAWN	变更内容 DESCRIPTION	日期 DATE	GENERAL TOLERANCE		制图 DRAWING	ROSE			料号 PART NO.	ZX-HA2.54-NPLT-XM		版本 REV.	A
			.X±0.30	X.°±5°	审核 CHECK	LEO			品名 TITLE	HA-SMT-A带扣针座		页次 SHEET	1/1
			.XX±0.25	X.X°±3°	核准 APPROVAL	JOHN			客户料号 CUTM.NO.				
			.XXX±0.20	X.XX°±1°									
					单位 UNITS	MM	比例 SCALE	1:1	兆星精密电子（深圳）有限公司 ShenZhen ZhaoXing Precision electronics Co., Ltd.				