


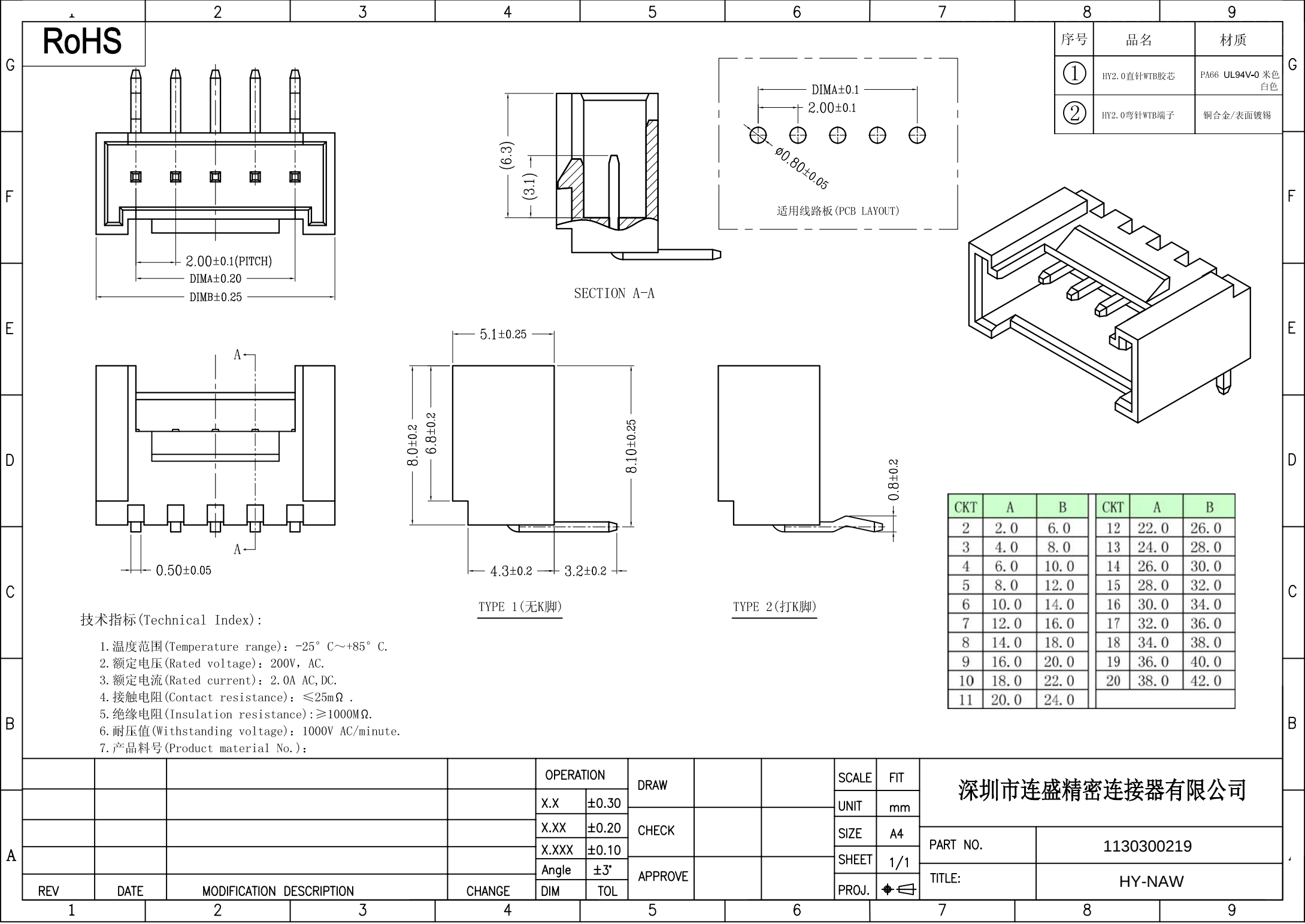

RoHS

序号	品名	材质
①	HY2.0直针WTB胶芯	PA66 UL94V-0 米色 白色
②	HY2.0弯针WTB端子	铜合金/表面镀锡

CKT	A	B	CKT	A	B
2	2.0	6.0	12	22.0	26.0
3	4.0	8.0	13	24.0	28.0
4	6.0	10.0	14	26.0	30.0
5	8.0	12.0	15	28.0	32.0
6	10.0	14.0	16	30.0	34.0
7	12.0	16.0	17	32.0	36.0
8	14.0	18.0	18	34.0	38.0
9	16.0	20.0	19	36.0	40.0
10	18.0	22.0	20	38.0	42.0
11	20.0	24.0			

技术指标(Technical Index):

- 温度范围(Temperature range): $-25^{\circ}\text{C} \sim +85^{\circ}\text{C}$.
- 额定电压(Rated voltage): 200V, AC.
- 额定电流(Rated current): 2.0A AC, DC.
- 接触电阻(Contact resistance): $\leq 25\text{m}\Omega$.
- 绝缘电阻(Insulation resistance): $\geq 1000\text{M}\Omega$.
- 耐压值(Withstanding voltage): 1000V AC/minute.
- 产品料号(Product material No.):