


Differential Probe DP-60HS

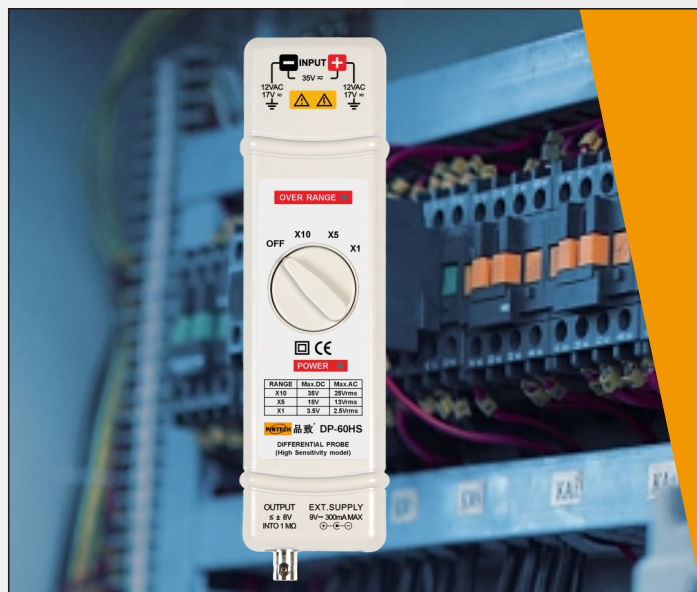

Characteristic

- 2% accuracy.
- Adaptor power supply.
- Standard BNC interface, compatible with any brand's oscilloscope.

Model	DP-60HS
Bandwidth(-3dB)	1X:DC-15MHz; 5X:DC-50MHz; 10X:DC-60MHz
Attenuation Ratio	1X,5X,10X
Accuracy	±2%
Rise Time	≥5.8ns
Input differential Vp-p	1X:7V; 5X:36V; 10X:70V
Input differential V AC RMS	25V
Input differential V DC	1X:3.5V; 5X:18V; 10X:35V
Common mode voltage(rms)	12V
Input Impedance	0.5MΩ//20pF(Single-ended); 1MΩ//10pF(Both ends)
Noise RMS	≤1mV rms
Oscilloscope input impedance	1MΩ
Power adaptor	9V adapter
CMRR(Typical)	60Hz:>80dB; 100Hz:>60dB; 1MHz:>50dB
Temperature	0~50°C
Humidity	10~85%RH
Weight	250g
Dimension(L*W*H)	195×55×30mm

● ACCESSORIES



9V Adapter



BP-250



BP-256N



BP-276N



BP-356N

GUANGZHOU PINTECH CO.,LTD

Web:www.pintech.com.cn

Tel:020-82510899

E-mail:sales@pintech.com.cn

Main Products

Optical Isolated Voltage Probe, Differential probe, Oscilloscope probe, High voltage probe, High frequency current probe, Current probe, Digital high voltage meter, High voltage amplifier, Power amplifier, ESD generator, Function generator, Oscilloscope, Spectrum analyzer, multimeter, High voltage power supply, AC power supply, DC power supply and Power equipment instrument.