
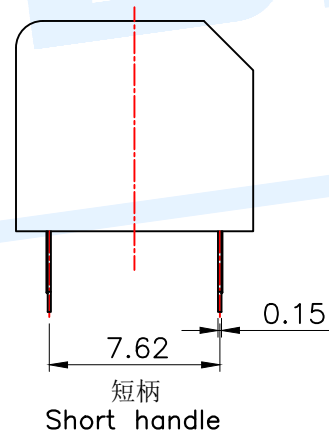
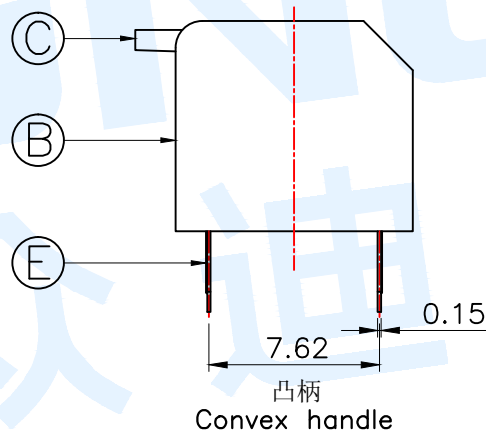
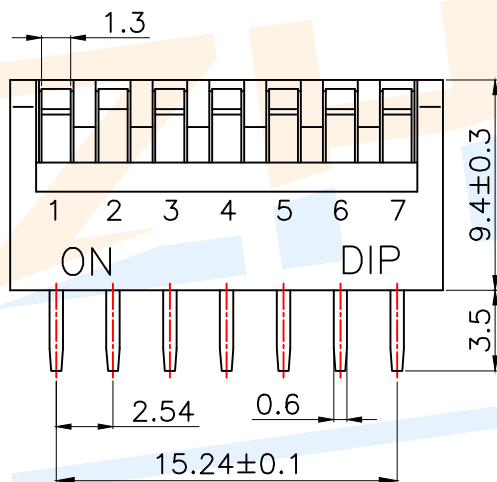
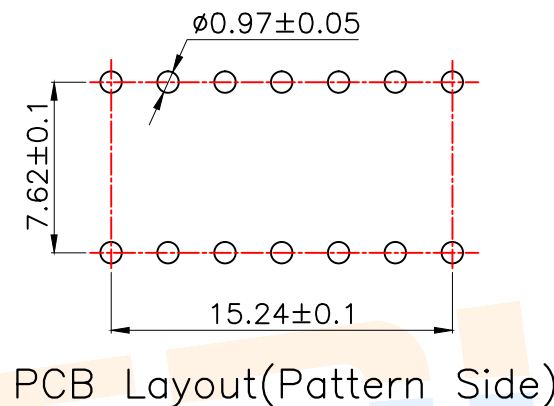
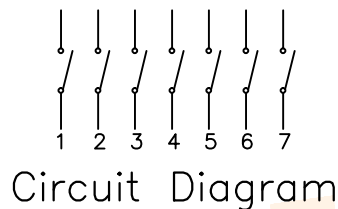


RoHS

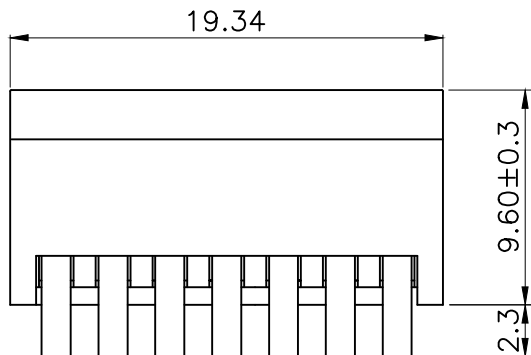

NOTE:
1.Rating: 24V 25mA DC
2.Insulation Resistance:≥100 MΩ
3.Withstand voltage:AC 500V 1Minute
4.Operating Force Range: 1000gf Max
5.Mechanical Life:3,000 Cycles

Number of digits(位数)		1P	2P	3P	4P	5P	6P	7P	8P	9P	10P	12P
Cover/red 盖子/红色	凸柄 Convex handle	DP-01	DP-02	DP-03	DP-04	DP-05	DP-06	DP-07	DP-08	DP-09	DP-10	DP-12
	短柄 Short handle	DP-01D	DP-02D	DP-03D	DP-04D	DP-05D	DP-06D	DP-07D	DP-08D	DP-09D	DP-10D	DP-12D
Cover/blue 盖子/蓝色	凸柄 Convex handle	DP-01R	DP-02R	DP-03R	DP-04R	DP-05R	DP-06R	DP-07R	DP-08R	DP-09R	DP-10R	DP-12R
	短柄 Short handle	DP-01L	DP-02L	DP-03L	DP-04L	DP-05L	DP-06L	DP-07L	DP-08L	DP-09L	DP-10L	DP-12L

Ⓔ	Terminal		14	Phosphorus bronze	Gold plating
Ⓓ	Potting glue			Epoxy resin	Black
Ⓒ	Handle		7	PBT	White
Ⓑ	Cover		1	PBT	Red/Blue
Ⓐ	Base		1	PBT	Black
NO.	Name	Number	Qty	Materil	Remarks
ZHONGDI® Zhongdi Electronic Technology Co., Ltd					
design		date		name	
Review		date		DIP SWITCH	
Approved		date		model	
number:				DP-07	
pr	1:1	unit	mm	gape number	A4