

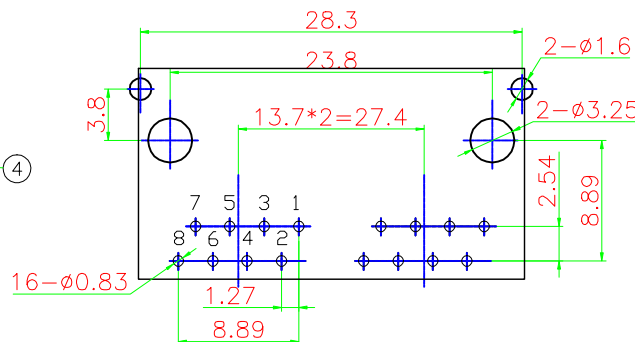
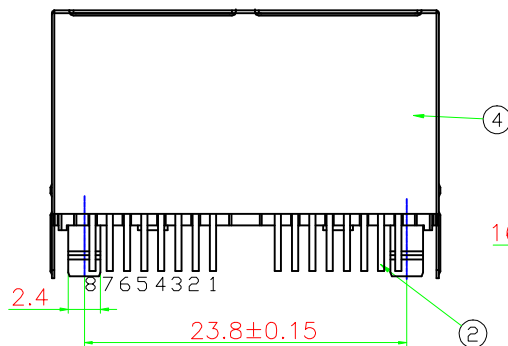
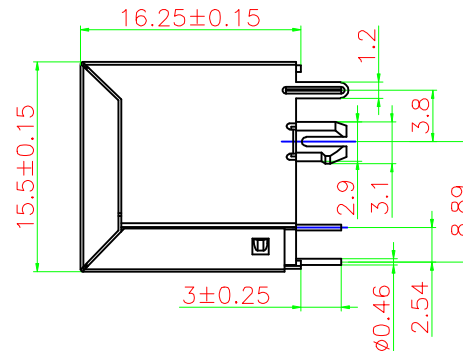


 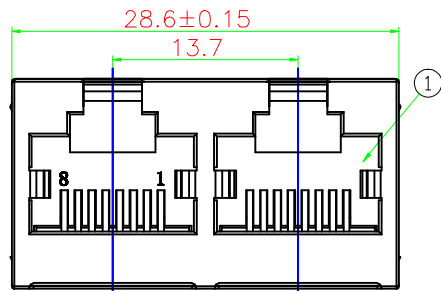


General Specification
Current Rating: 1.5A DC /Contact, 20mA DC for LED signals
Voltage Rating: 125V AC /Contact, 2.0 volts DC for LED signals
Operating Environment
Standard Temperature: -20℃~+70℃
Industrial Temperature: -40℃~+85℃
Humidity: 20~70%
Contact Resistance: <30mΩ
Insulation Resistance: >500MΩ
Dielectric Strength: 500V AC/(50HZ)/Min
Mating And Unmating Force: 3~20N
Durability: 750 Cycles Min

Material Specification
Housing :Thermo-plastic, UL94V-0.
Contact :Alloy Copper
Shield :Alloy Copper
Please refer to the customer drawing when customer has specified

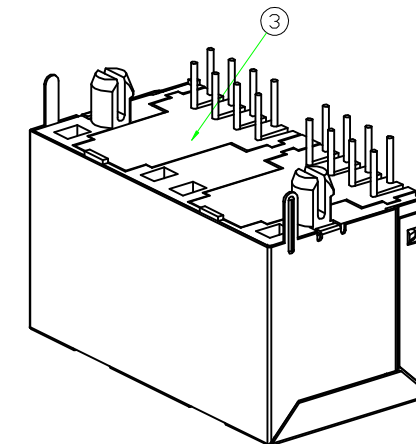

4	外壳	H62	1	NI	
3	后盖	PA46	2	BLACK	
2	插针	PHOSPHOR BRONZE	16	1U"	
1	塑座	PA46	1	BLACK	
序号	名称	材料	数量	镀层/颜色	备注



一般公差		品名:	RCH-5242-12(无灯前脚3.8)		
30~	±0.25	料号:	RC01186		
10~30	±0.20	型号:	RJ45	图号:	
~10	±0.15	版本:	单位:mm	比例: 1:1	纸张: A4
角度:	±2°	页面:	1 of 1		

网络插座外形图

绘图:	吴鹏飞	日期:	2022.4.6
审核:	陈德	日期:	
核准:	李生	日期:	

A/0

新出版发行

版次

变更履历

变更单号

绘制

日期

核准

日期

1

2

3

该图面供温州瑞川电子有限公司内部使用,不得私自复印