


產品編碼 P/N	PSPMAA0412~2213 Series	測試設備 TEST INSTRUMENT	Chroma 3302 16502
產品系列 Series	一体成型电感	測試頻率 TEST FREQUENCY	100KHZ/1V

封裝尺寸
Dimension (mm)

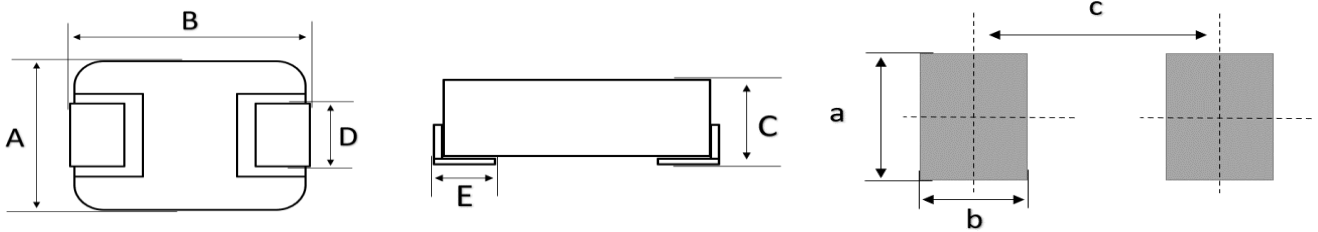

系列	封裝尺寸 Dimension					焊盤尺寸 Land Pattern		
Series	A	B	C	D	E	a	b	c
063T	6.6±0.3	7.1±0.3	3.0MAX	3.0±0.5	1.6±0.5	3.5Typ	2.1Typ	5.8Typ

063T Series

產品編碼 P/N	@ 25 °C Ambient Temperture					
	感值	公差	DCR		溫升電流 (IRMS)	飽和電流 (ISAT)
	Inductance	Tolerance	mΩ		A	A
	μH	±	Typ	Max	ΔT≈40℃	L0 drop≈30%
PSPMAA063T-R10M-ANP	0.10	20%	1.3	1.5	33.0	60.0
PSPMAA063T-R15M-ANP	0.15	20%	1.3	1.5	33.0	55.0
PSPMAA063T-R22M-ANP	0.22	20%	1.5	1.7	32.0	50.0
PSPMAA063T-R33M-ANP	0.33	20%	3.0	3.5	21.0	25.0
PSPMAA063T-R36M-ANP	0.36	20%	3.3	3.9	20.0	24.0
PSPMAA063T-R47M-ANP	0.47	20%	3.5	4.1	18.0	20.0
PSPMAA063T-R56M-ANP	0.56	20%	3.9	4.5	16.5	18.0
PSPMAA063T-R68M-ANP	0.68	20%	4.8	5.3	16.0	17.0
PSPMAA063T-R82M-ANP	0.82	20%	5.4	6.0	14.0	16.0
PSPMAA063T-1R0M-ANP	1.00	20%	6.7	7.4	12.0	15.0
PSPMAA063T-1R2M-ANP	1.20	20%	7.8	10.0	10.0	14.0
PSPMAA063T-1R5M-ANP	1.50	20%	10.6	12.0	10.0	14.0
PSPMAA063T-2R2M-ANP	2.20	20%	13.5	15.0	8.0	10.0
PSPMAA063T-2R5M-ANP	2.50	20%	16.0	18.0	7.0	10.0
PSPMAA063T-3R3M-ANP	3.30	20%	18.0	22.0	6.5	9.5
PSPMAA063T-4R7M-ANP	4.70	20%	28.0	33.0	5.5	7.6
PSPMAA063T-5R6M-ANP	5.60	20%	39.0	42.0	5.5	6.0
PSPMAA063T-6R8M-ANP	6.80	20%	43.0	50.0	4.5	6.0
PSPMAA063T-8R2M-ANP	8.20	20%	54.0	60.0	4.5	6.0
PSPMAA063T-100M-ANP	10.00	20%	62.0	68.0	5.0	5.5

