
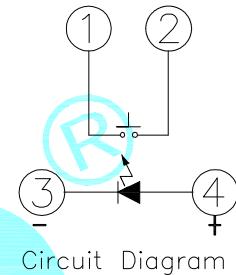


PCB Layout(pattern Side)

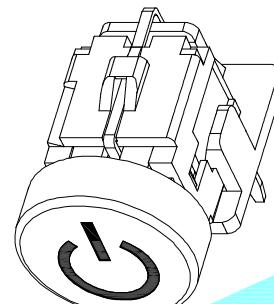

LED colour(LED颜色)	Part No. (料号)
White(白色)	K6-6277D-01
Red(红色)	K6-6277D-02
Blue(蓝色)	K6-6277D-03
Green(普绿)	K6-6277D-04
Yellow(黄色)	K6-6277D-05
Orange(橙色)	K6-6277D-06
Jade Green(翠绿色)	K6-6277D-07
Red(红色)/Blue(蓝色)	K6-6277D-23
Red(红色)/White(白色)	K6-6277D-21
Red(红色)/Jade Green(翠绿色)	K6-6277D-27

Typical Specifications

- 1.Rating : DC 30V 0.3A
- 2.Operating Force : 250 ± 50 gf
- 3.Contact Resistance : 100mΩMAX
- 4.Life : 100,000 Cycles Min

②	Terminal	4		Phosphor bronze	Au Plating	
①	Housing	1		Nylon	Black	
ITEM	PART NAME	TER'NO.	QTY.	MATERIAL	FINISHING	REMARK
APPROVALS		DATE		hro®		
DRAWN	J.X.Zhang	2018/08/01				
CHECKED				TITLE:	LED Tact Switch	
APPROVALS				PART NO.	K6-6277D-□□	
TOLERANCES ARE		30~以上 10~30 5~10 ~ 5	±0.30 ±0.20 ±0.15 ±0.10	ANGLE UNIT: mm SCALE: 1:1 DRAWING NO.	PROJ:	
ECN NO.	REV.	DATE.	DESCRIPTION.	CHANGE.	CHECK.	APPRO.