

SMD Seam Crystal Units 3.2x2.5x0.70mm Series



Features

- . Extremely small SMD type crystal units.
- . Application for smart phone, sip module ,variety of compact portable consumer products reference clocks.
- . High reliable environmental performance






Electrical Specifications

Item / Type	
Frequency Range 频率范围	8.00 ~ 64.00MHz
Frequency Tolerance (at 25 °c) 调频偏差	± 10 ppm ± 20 ppm, or specify
Frequency Stability 频率温度特性	± 10 ppm ± 20 ppm, or specify
Operating Temperature Range 工作温度	-40 ~ +85 °c -40 ~ +105 °c, or specify
Shunt Capacitance (C0) 静态电容	3 pF Max. (2 pF typical)
Drive Level 激励功率	10 μW~200μW (Max 100 μW)
Load Capacitance 负载电容	6pF 8pF 9pF 10pF 12pF 20pF, or specify
Aging (at 25 °c) 老化率	± 3 ppm year Max.
Storage Temperature Range 存储温度	- 5 5 ~ + 125 °c

Equivalent Series Resistance(ESR)

Fundamental			
8~11.0592 MHz	150 Ω Max.	12~16MHz	50 Ω Max.
17~39 MHz	40 Ω Max.	40~64 MHz	30 Ω Max.

Dimensions

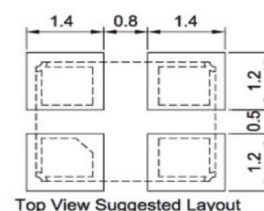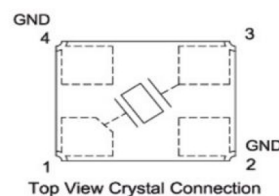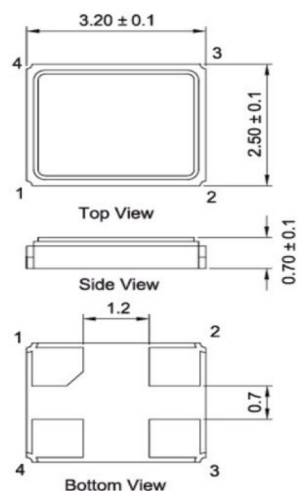

Units: mm