



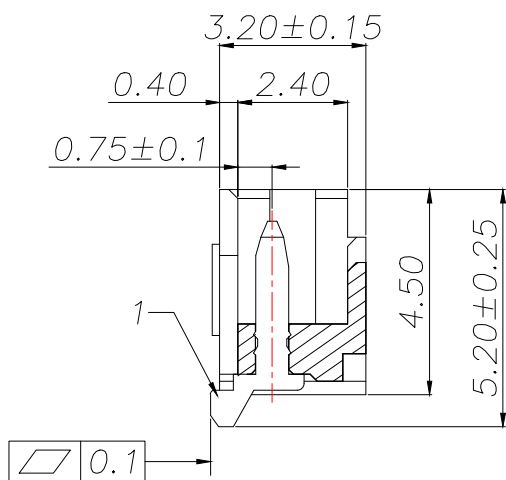


说明:

- 1.产品表面清洁,无锈蚀、氧化、裂纹、缺芯、毛刺、及其它机械损伤;
- 2.塑胶材料:LCP UL94V-0,颜色:本色;
- 3.焊片:黄铜,镍底30u"Min.,镀锡50u"Min.;
- 4.接触针:黄铜,镍底30u"Min.,镀锡50u"Min.;
- 5.满足灼热丝温度850度.
- 6.工作温度-40~+85°C
- 7.额定电流:1A AC/DC
- 8.额定电压:125V AC/DC
- 9.接触阻抗:20mΩ Max.
- 10.绝缘阻抗:500MΩ Min.
- 11.耐电压:250V AC FOR 1 MINUTE



序号	名称	数量
1	接触针	n
2	定位焊片	2
3	基座	1

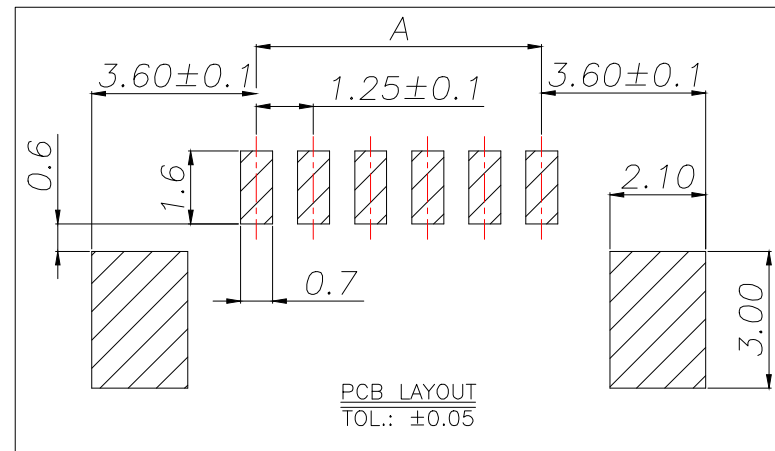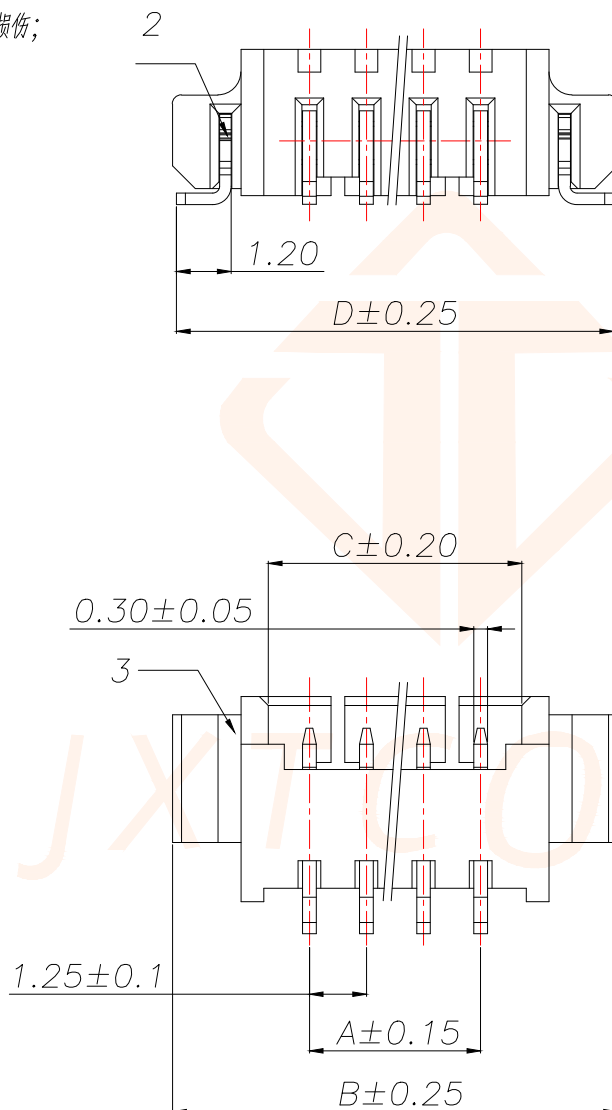

P/N	PIN	DIM A	DIM B	DIM C	DIM D
JXT-MX1.25-2PWT	2	1.25	7.25	3.05	7.08
JXT-MX1.25-3PWT	3	2.50	8.50	4.30	8.33
JXT-MX1.25-4PWT	4	3.75	9.75	5.55	9.58
JXT-MX1.25-5PWT	5	5.00	11.00	6.80	10.83
JXT-MX1.25-6PWT	6	6.25	12.25	8.05	12.08
JXT-MX1.25-7PWT	7	7.50	13.50	9.30	13.33
JXT-MX1.25-8PWT	8	8.75	14.75	10.55	14.58
JXT-MX1.25-9PWT	9	10.00	16.00	11.80	15.83
JXT-MX1.25-10PWT	10	11.25	17.25	13.05	17.08
JXT-MX1.25-11PWT	11	12.50	18.50	14.30	18.33
JXT-MX1.25-12PWT	12	13.75	19.75	15.55	19.58
JXT-MX1.25-13PWT	13	15.00	21.00	16.80	20.83
JXT-MX1.25-14PWT	14	16.25	22.25	18.05	22.08
JXT-MX1.25-15PWT	15	17.50	23.50	19.30	23.33
JXT-MX1.25-16PWT	16	18.75	24.75	20.55	24.58
JXT-MX1.25-17PWT	17	20.00	26.00	21.80	25.83
JXT-MX1.25-18PWT	18	21.25	27.25	23.05	27.08
JXT-MX1.25-19PWT	19	22.50	28.50	24.30	28.33
JXT-MX1.25-20PWT	20	23.75	29.75	25.55	29.58

TOLERANCE		深圳聚兴泰电子科技有限公司 Shenzhen Juxingtai Electronic Technology Co., Ltd			
X.:±0.30	X':±5°	PART NO. JXT-MX1.25-XPWT	TITLE: TX-SMT-AW针座		
X.X:±0.25	X.X':±3°				
X.XX:±0.20	X.XX':±1°				
UNITS	mm	DESIGN: Ethan	MANUFACTURE DWG		
MATERILA	— — —	CHED: Olvia			
FINISH	— — —	APPD: Ava			
				SCALE N:A	SHEET 1/1