

Rohs

SPECIFICATIONS

Rated Current:1.5AMP

Contact Resistance: 20m Ω Max

Withstand Voltage:400V AC/DC

Insulation Resistance: 800M Ω Min

Operation Temperature: -40°C to $+105^{\circ}\text{C}$

Contact Material: Brass



Contact Plating: Au Over Ni

Insulator Material: Polyester (UL94V-0)

Standard: PA6T

Max. Processing Temp: 230°C for 30–60 seconds

(260°C for 10 seconds)

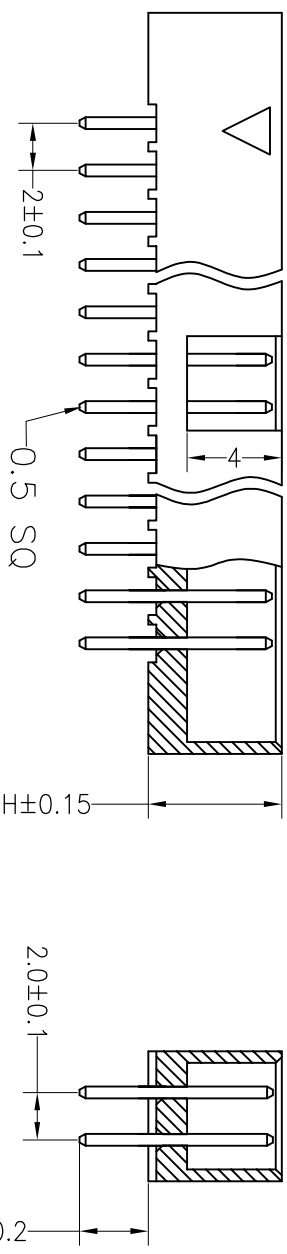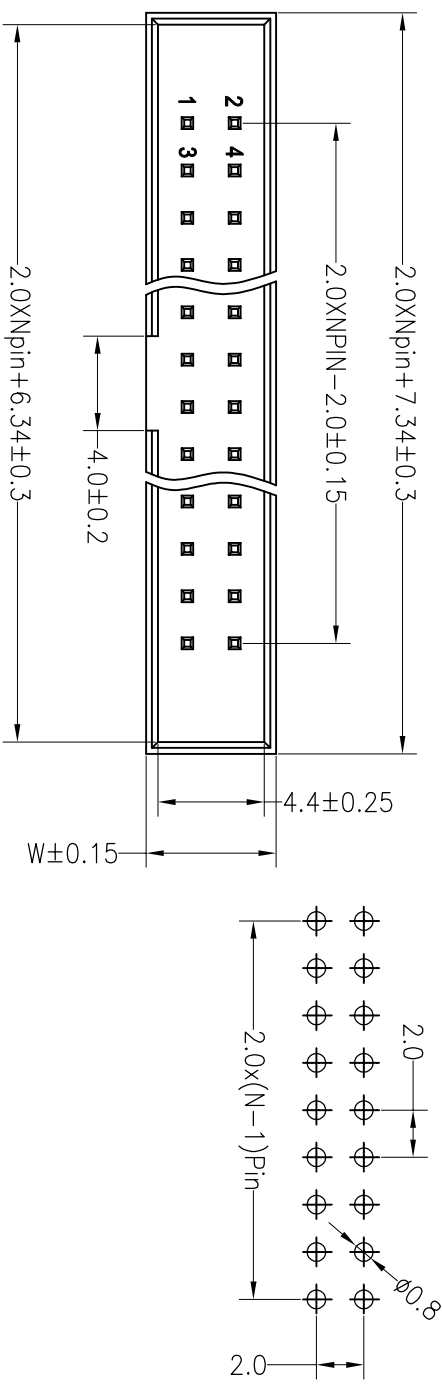

Ordering Information

[illegible]

产品类型	间距	总Pin数	产品形态	电镀厚度	塑胶材料	塑胶颜色	包装方式	序列号
1=筒牛	1=1.27	016=16P	1=DIP	00=常规	1=PB1	1=黑色	1=管装	0001-9999

3=SM T
4=SH
5=蜈蚣脚

SIV=後場

6=真巴
7=古古

7=灰白色

Dimension antitheses list					
ITEM	PB	PC	PW	H	W
001		2.8		5.65	5.5
002					

					OPERATION						深圳市连盛精密连接器有限公司				
					X.X	±0.30	DRAW								
					X.XX	±0.20		CHECK							
					X.XXX	±0.10									
					Angle	±3°									
REV	DATE	MODIFICATION	DESCRIPTION	CHANGE	DIM	TOL	APPROVE				SCALE	FIT	PART NO. 1030200125		
											UNIT	mm			TITLE: 2.0Box Npin H5.65 180°
											SIZE	A4			
A0	2012.03.28		NEW DRAWING								SHEET	1/1			
											PROJ.				