

Rohs

SPECIFICATIONS

Rated Current:3.0AMP

Contact Resistance: 20m Ω Max

Withstand Voltage:1000V AC/DC

Insulation Resistance: 1000M Ω Min

Operation Temperature: -40°C to $+105^{\circ}\text{C}$

Contact Material:Brass


Contact Plating: Au Over Ni

Insulator Material: Polyester (UL94V-0)




Standard: PBT

Max.Processing Temp: 180°C for 30–60 seconds

(200°C for 10 seconds)

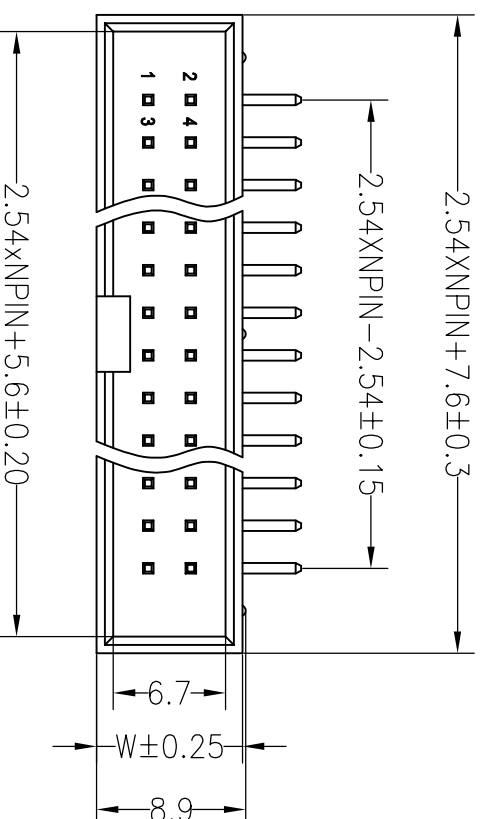

Recommended P.C.B Layout(Top Side)
(PCB BOARD TOLERANCE $\pm$ 0.05)

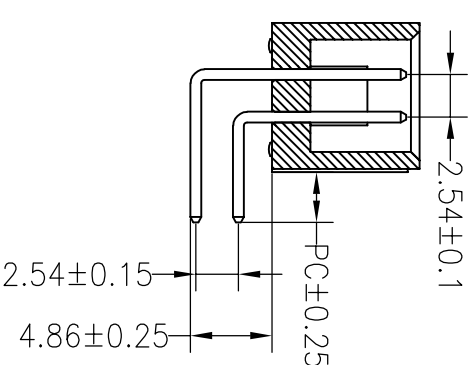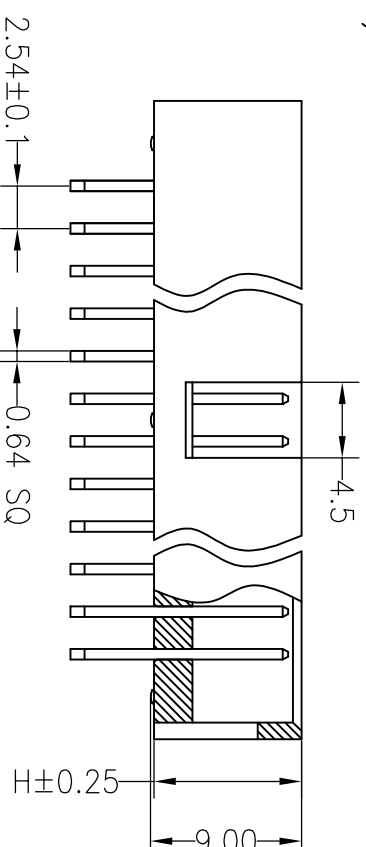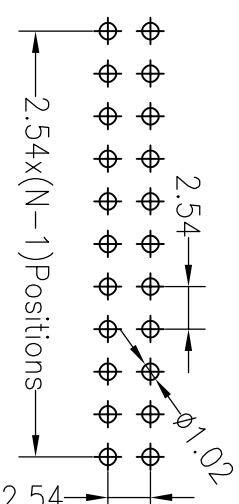

Ordering Information

产品类别	1=牛肉	J	X	XXX	X	XX	X	X	XXXX
产地	1=27								
总页数	016=1P								
产品形态	1=OP								
电焊厚度	00=收线								
塑胶材料	1=BT								
塑胶颜色	1=黑色								
包装方式	1=管装								
序列号	0001-9999								

产品系列	产品形状	电导率	塑胶材料	颜色	包装形式	序号
J=黄铜	1=1.27	00=绝缘	1=PET	1=黑色	1=背胶	001-9999
	2=2.0	01=11μ	2=LCP	2=白色	2=透胶	
	3=3.0	02=2μ	3=PPS	3=白色	3=透胶	
	4=4.5	03=3μ	4=PA66	4=蓝色	4=透胶	
	5=1.0	04=4μ	5=PA6T	5=红色	5=透胶	
	6=0.8	05=5μ	6=PA6T	6=黄色		
	7=5.08	06=6μ	7=PA6T	7=灰白色		
	A=12.7/2.54					

Dimension antitheses list					
ITEM	PB	PC	PW	H	W
001		3.0		8.8	8.7
002					

[illegible]