

产 品/Product : **2G/3G/4G,NB-IoT,CAT.1&4, H250 FiberGlass Antenna**

料 号/PN : **AH3G.501**

应 用/Application : **2G/3G/4G,NB-IoT,CAT.1&4, Remote /Transfer /Recciever ;**



电气参数(Electrical Properties)

频率/Frequency:	800~2170 MHz, 2G/3G/4G,NB-IoT,CAT. 1&4
输入阻抗/Impedance:	50 Ω
驻波比/VSWR:	≤ 2.0
增益/Gain:	3.5/4.5 dBi
极化方式/Polarization:	Vertical / Omni

机械参数(Mechanical Properties)

接头&线缆/Conn&Cable:	N-J Type
材料&颜色/Material&Color:	Copper/ FiberGlass
安装方式/Mounting:	/
尺寸/Size:	$\phi 22 \times L250$ mm
重量/Weight:	35.0 g/pcs
工作温度/Operate Temp:	-40 ~ +85 $^{\circ}\text{C}$

关联产品/Relation Product



SMA-K DIP ([AHCG.202](#))



SMA-K ASSY ([AHCG.101](#))





MetalSpring ([AH3G.402](#))

产品手册/ Product Catalogue



下载地址/Download Link: <http://docs.AntennaHome.com/ant/catalogue.pdf>

免费样品申请
Ask free sample

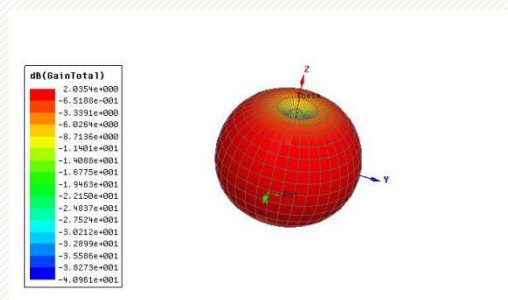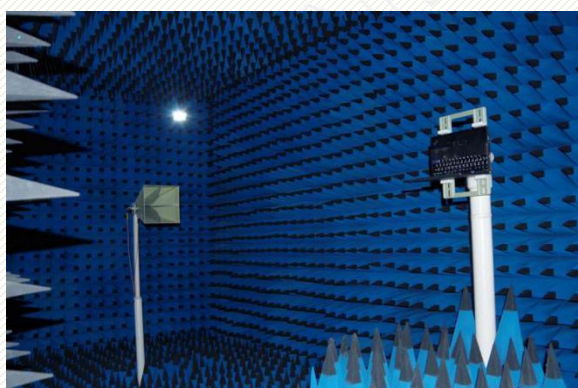

Online Support

Contact Us

E-mail : CS@AntennaHome.com

Website : [Http://www.AntennaHome.com](http://www.AntennaHome.com)