

A





B

C

D

E

F

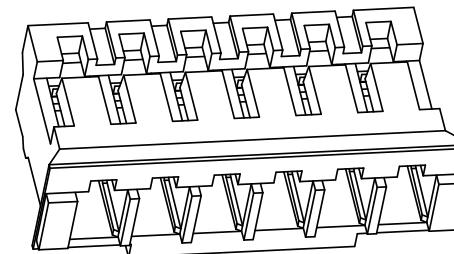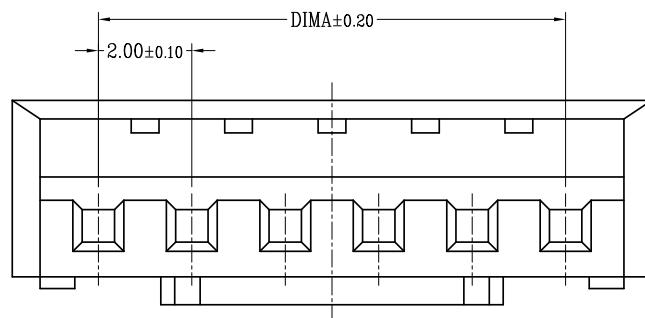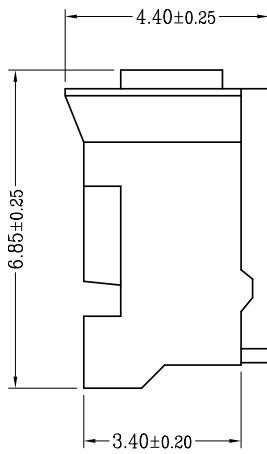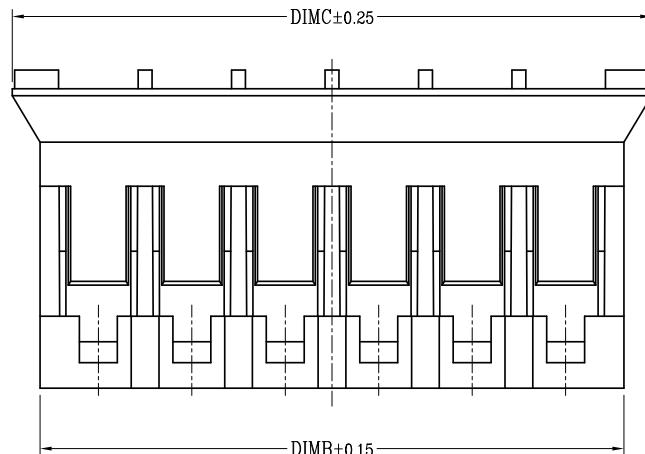

### 技术指标:

1. 温度范围:  $-40^{\circ}\text{C} \sim 85^{\circ}\text{C}$ .
2. 额定电压: 200V AC, DC.
3. 耐电压: 200V AC/minute.
4. 接触电阻:  $\leq 25\text{m}\Omega$ .
5. 绝缘电阻:  $\geq 1000\text{M}\Omega$ .
6. 额定电流: 2A AC, DC.

CKT	A	B	C
2	2.00	4.50	5.70
3	4.00	6.50	7.70
4	6.00	8.50	9.70
5	8.00	10.50	11.70
6	10.00	12.50	13.70
7	12.00	14.50	15.70
8	14.00	16.50	17.70
9	16.00	18.50	19.70
10	18.00	20.50	21.70
11	20.00	22.50	23.70
12	22.00	24.50	25.70
13	24.00	26.50	27.70
14	26.00	28.50	29.70
15	28.00	30.50	31.70
16	30.00	32.50	33.70



深 圳 市 华 德 共 创 科 技 有 限 公 司

Shenzhen Huade co-create Technology Co., LTD

TEL : 0755-27111216 FAX : 0755-29940187

-TOLERANCES- UNLESS OTHERWISE SPECIFIED 公差参数表		APPD: 核准: 谢亮	TITLE: 产品名称: 20010HS-NN	
X.X	± 0.30	X.X* ± 3°	CHECK: 校对: 王建业	PART NO: 产品编号: 20010HS-NN-HDGC2001
X.XX	± 0.30	X.XX* ± 2°	DRAW: 绘图: 黄艳兰	DATE 2013-05-07
X.XXX	± 0.10	X.XXX* ± 1°	SCALE 1 : 1	UNIT mm
			CODE NUMBER A003	