


产 品/Product : **L280 FiberGlass , N-type ,1575.42/1561MHz GNSS Antenna**

料 号/PN : **AHGG.501**

应 用/Application : GNSS/GPS/BD system, tracker/location Transfer /Recciever ;

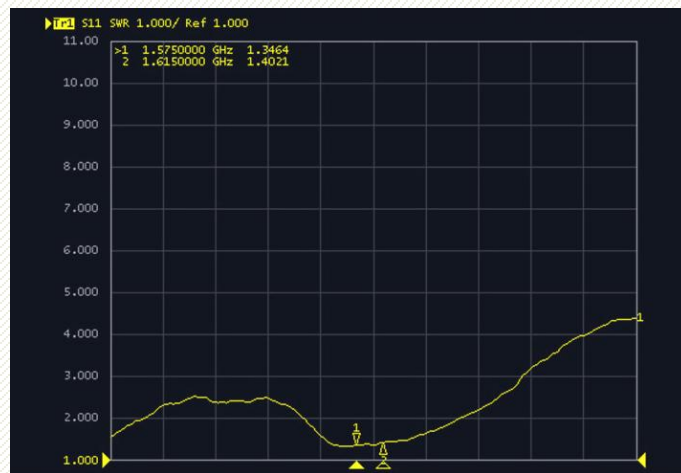

电气参数(Electrical Properties)

频率/Frequency:	GPS/1575.42 MHz、BD/1561.02MHz、
输入阻抗/Impedance:	50 Ω
驻波比/VSWR:	≤ 2.0
增益/Gain:	3.8 dBi
极化方式/Polarization:	Vertical / Omni

机械参数(Mechanical Properties)

接头&线缆/Conn&Cable:	N-J Type
材料&颜色/Material&Color:	Copper/FiberGlass
安装方式/Mounting:	/
尺寸/Size:	$\phi 22 \times L280$ mm
重量/Weight:	130 g/pcs
工作温度/Operate Temp:	-40 ~ +85 $^{\circ}\text{C}$

关联产品/Relation Product



H50 Rubber ([AH1G.101](#))



PCB IPX ([AH1G.201](#))





H175 Rubber Magnetic
([AH1G.401](#))

产品手册/ Product Catalogue



下载地址/Download Link: <http://docs.AntennaHome.com/ant/catalogue.pdf>

免费样品申请
Ask free sample

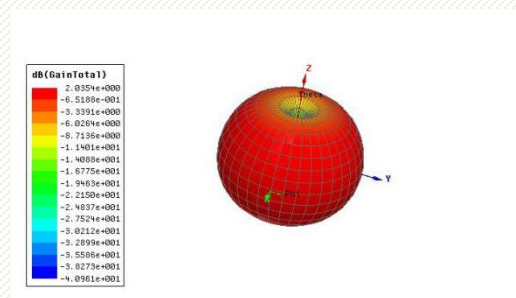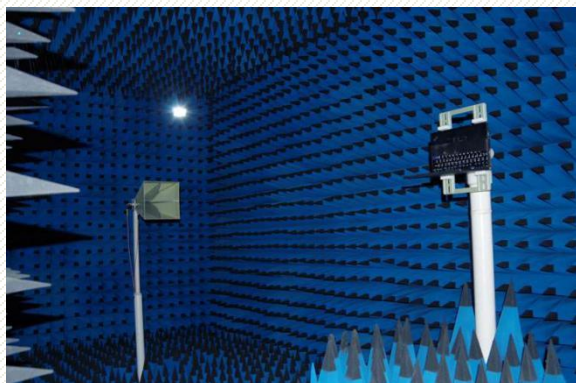

Online Support

Contact Us

E-mail : CS@AntennaHome.com

Website : [Http://www.AntennaHome.com](http://www.AntennaHome.com)