


产 品/Product : **H200 Rubber SMA-J** ,868MHz /915MHz GSM900/ 1800M Antenna

料 号/PN : **AH2G.107**

应 用/Application : LoRa868/915M,GSM 900/1800M includesfrequenciesof 868/915M wireless products

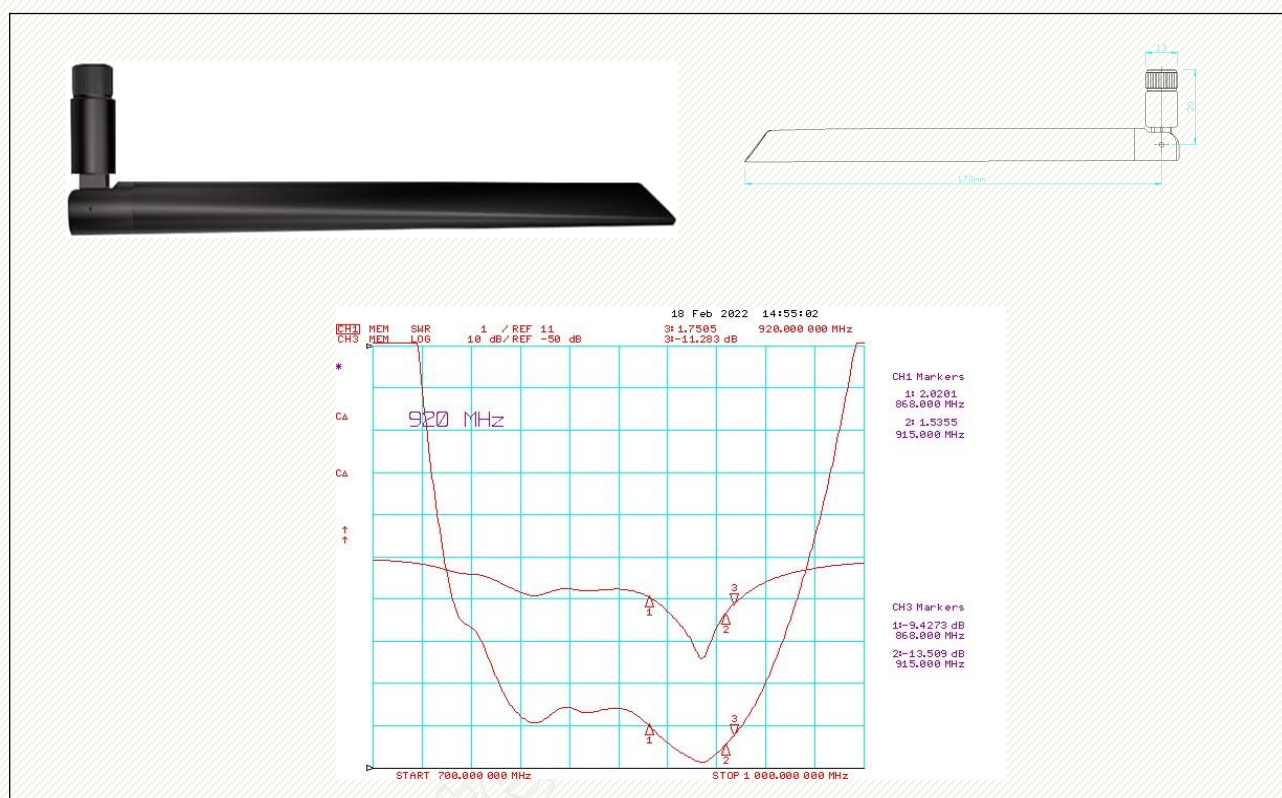

电气参数(Electrical Properties)

频率/Frequency:	868/915MHz , 2G/3G
输入阻抗/Impedance:	50 Ω
驻波比/VSWR:	≤ 3.5
增益/Gain:	5 dBi
极化方式/Polarization:	Vertical / Omni

机械参数(Mechanical Properties)

接头&线缆/Conn&Cable:	SMA-J
材料&颜色/Material&Color:	Copper / ABS
安装方式/Mounting:	SMA connector
尺寸/Size:	$\phi 13 \times H200$ mm
重量/Weight:	9.0 g/pcs
工作温度/Operate Temp:	-40 ~ +85 $^{\circ}\text{C}$

关联产品/Relation Product



SMA-K DIP ([AHCG.202](#))



SMA-K ASSY ([AHCG.101](#))



PCB 2.4G ([AH2G.201](#))





H200 FiberGlass ([AH2G.501](#))

产品手册/ Product Catalogue



下载地址/Download Link: <http://docs.AntennaHome.com/ant/catalogue.pdf>

免费样品申请
Ask free sample

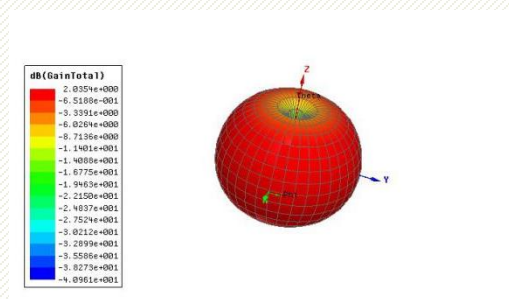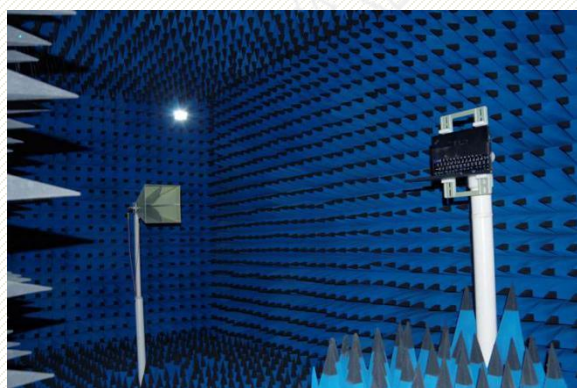

Online Support

Contact Us

E-mail : CS@AntennaHome.com

Website : [Http://www.AntennaHome.com](http://www.AntennaHome.com)