 


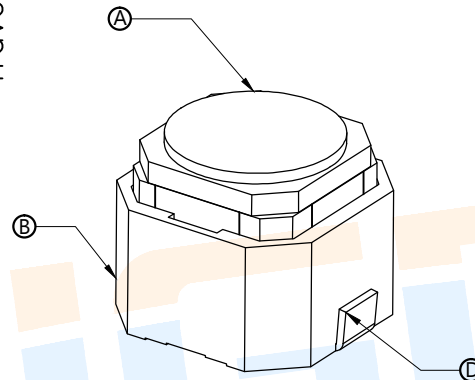
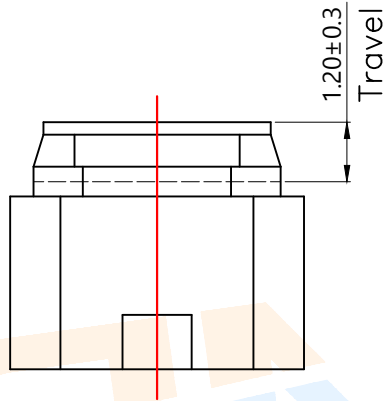
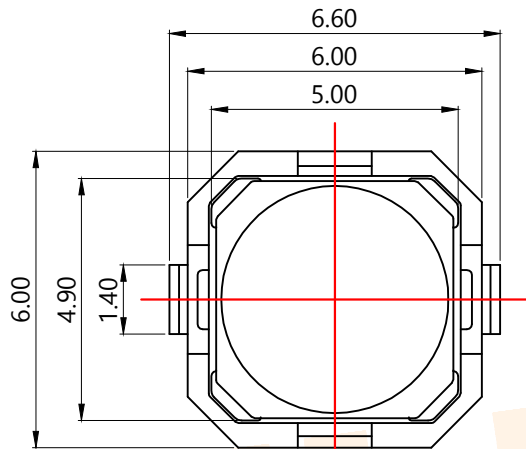
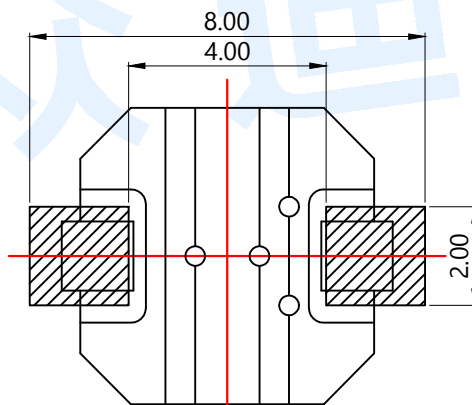


RoHS

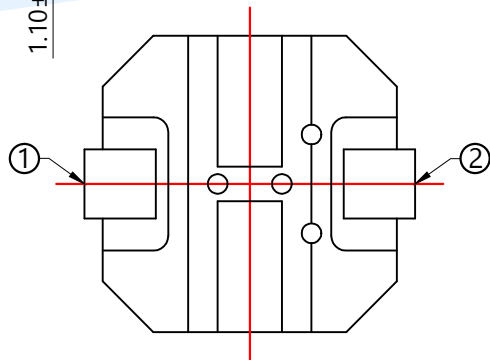

TOTAL HEIGHT		Travel
Code	H	
043	4.3	0.7±0.3
050	5.0	1.2±0.3

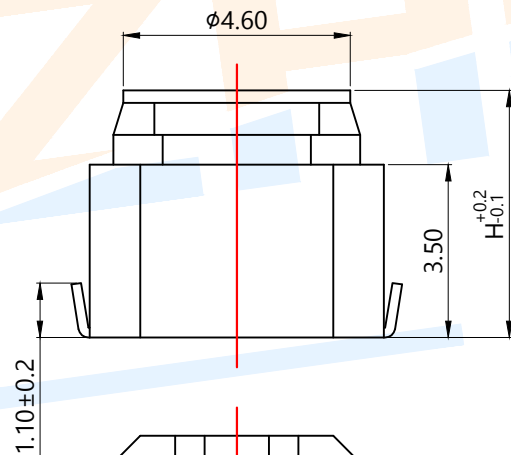

PCB Layout(Pattern Side)

Product No. : TS-068-□□-□□
型号: ———
产品高度 (H) :
043=4.3mm
050=5.0mm
操作力度 :
180=180gf±50gf
250=250gf±50gf
: 包装方式
-P=编带 (非编带, 不启用)
: 弹片
D1=C5210/1PCS

⑤	Waterproof silicone		1	Silica gel	
④	Terminal		2	Phosphor bronze	Silvering
③	Reed		1	Phosphor bronze	Silver covered
②	Base		1	LCP	Black
①	Button		1	LCP	Black

NO.	Name	Number	Qty	Materil	Remarks
ZHONGDI® Zhongdi Electronic Technology Co., Ltd					
design	date		name	TACT SWITCHS	
Review	date		model	TS-068-□□-D□	
Approved	date				

Drawing number: ———
Proportion 1:1 unit mm gaps number A4

modify Review Approved

angle	±2°
10~30	±0.30
5~10	±0.20
~ 5	±0.10

Tolerance not specified

项 目 Item	技术参数 Technical Parameter	标 准 Standard
电气性能 Electrical Properties	额定电流 Rated Current:	50mA
	额定电压 Rated voltage:	DC 12V
	接触电阻 Contact resistance:	≤100mΩ
	绝缘电阻 Insulation Resistance:	DC 250V 1 min ≥100MΩ
机械性能 Mechanical Properties	耐压强度 Compressive strength:	AC 250V 50Hz/1 min
	机械寿命 Mechanical life:	100,000 cycles Min
环境性能 Environmental	操作行程 Operation Stroke:	0.70/1.20±0.30mm
	工作温度 Operation temperature:	-25℃~ +75℃
可靠性特性 Reliability Characteristics	使用湿度 Use humidity:	≤85% RH
	回流焊 Reflow Soldering:	≤260℃ 时间 Time 3s
	波峰焊 Wave soldering:	≤260℃ 时间 Time 3s
应用领域 Application area	手工焊 Manual welding:	≥260℃ 时间 Time 3s
	影音产品、电子玩具、数码产品、通讯产品、安防产品等. Audiovisual products, electronic toys, digital products, communication products, security products, etc	



绝缘电阻测量仪



直流低电阻测试仪




耐电压测试仪



回流焊机



二次元测量仪

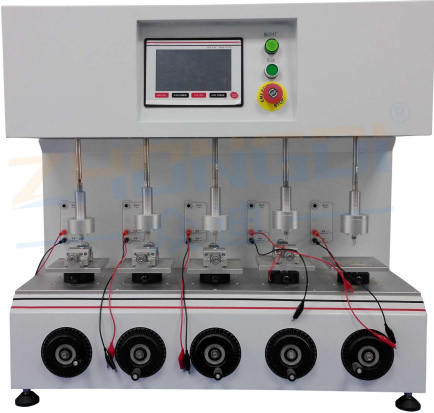

高精密寿命测试仪



盐雾测试仪



按键荷重曲线仪

ZHONGDI® 众迪										Zhongdi Electronic Technology Co., Ltd										
design			date			name			TACT SWITCHS											
Review			date			model			TS-068-□□-D□											
Approved			date			number:														
1:1		unit		mm		gape number		A4												