

HSF



ROHS

NOTE 说明:

1, Material材料:

a. Housing胶芯:LCP

b. Contact端子:C5210EH

(Surface Plating表面电镀:Sn锡 10u")

See Ordering Information 见订单信息

2, Electric电气性能:

a. Contact Resistance接触电阻:30 Milliohms Max 最大

b. Insulation Resistance绝缘电阻:1000 MEGA OHMS Min最小

c. Dielectric Voltage耐电压:500V AC交流

d. Operating Temperature工作温度: -55° To 105°

3. The dimension marked with "*" is key dimensions

带 "*" 尺寸为重点尺寸。

Order code:

BT	-	M	-	SN	-	R	-	CR2032N
①		②		③		④		⑤

① BT: Coin Cell Holders纽扣电池座 ③ Contact Plating 端子电镀

SN: Tin锡

G0: Gold flash 普金

G1: 3U" Gold 金

G2: 5U" Gold 金

G3: 10U" Gold 金

G4: 15U" Gold 金

G5: 30U" Gold 金


④ Packing method 包装方式

A: Tray packing 吸塑盒装


R: Tape & reel packing 卷装

⑤ Product number 产品编号


CR2032N

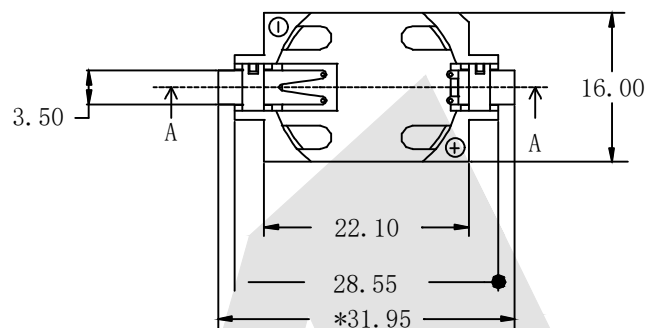

B*4 (NOTES 2)

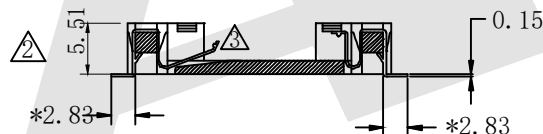

SECTION A-A

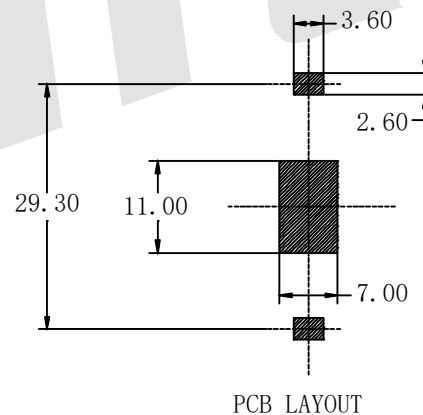

PCB LAYOUT

Unless Otherwise specified tolerance
X. ± 0.35 X. XX: ± 0.20
X. X: ± 0.25 X. XXX: ± 0.15



SCALE: As Shown	UNIT: mm
DRAW Mo Guo Xuan	DATE 03/14/2019
CHECK BobYang	DATE 03/14/2019



3rd ANGLE PROJECTION

TITLE: Coin Cell Holders For CR2032
CR2032纽扣电池座

DRAWING NO: BT-M-SN-R-CR2032N

PRODUCT NO: BT-M-SN-R-CR2032N

Change C5191 to C5210EH

08/22/2023

Delete Dimension删除尺寸 3.0

11/07/2022

Add Size 增加尺寸:5.51MM

02/23/2021

Change 修改 BT-M-G0-CR2032F to BT-M-G0-R-CR2032N

01/13/2019

REV

DESCRIPTION

DATE