

HSF



ROHS






NOTES:

- 1, BASE~
MAT'L: GLSAA FILED LCP UL 94V-0
2, CONTACTS:
MAT'L: 0.15mm TH'K PHOSPHOR BRONZE
FINISH: 1 u" GOLD FLASH, OVER NICKEL PLATE
3, OPERATING TEMPERATURE: 220° -255°
△ 4. 250 PCS per reel

 
Order code:

BT — M — G0 — R — CR2477A
① — ② — ③ — ④ — ⑤

- ① BT: Coin Cell Holders
② Appearance for the product
M: SMT TYPE
③ Contact Plating
SN: Tin
G0: Gold flash
G1: 3U" Gold
G2: 5U" Gold
G3: 10U" Gold
G4: 15U" Gold
G5: 30U" Gold
④ Packing method
A: Tray packing
R: Tape & reel packing
⑤ Product number
CR2477A

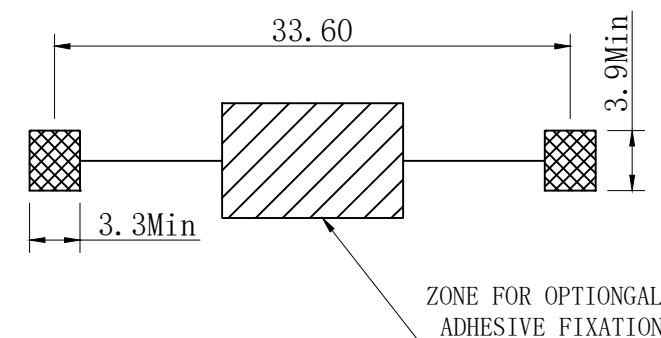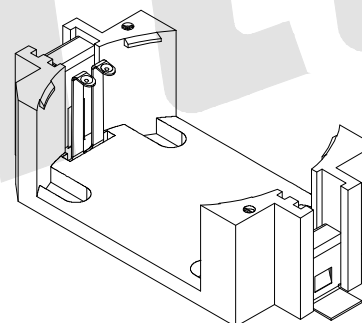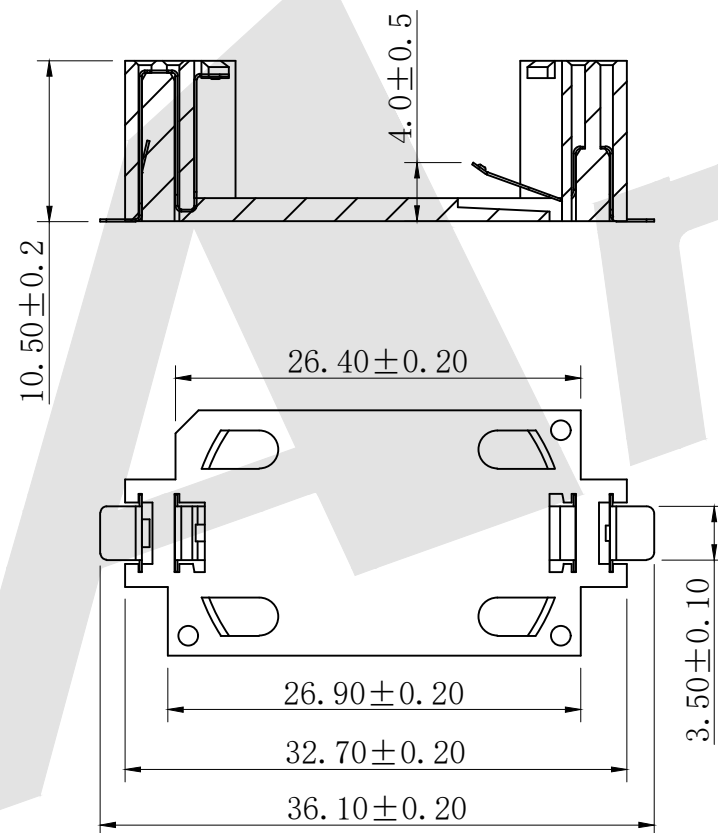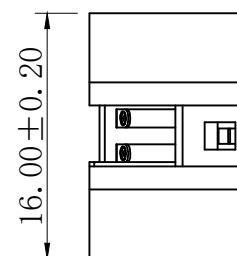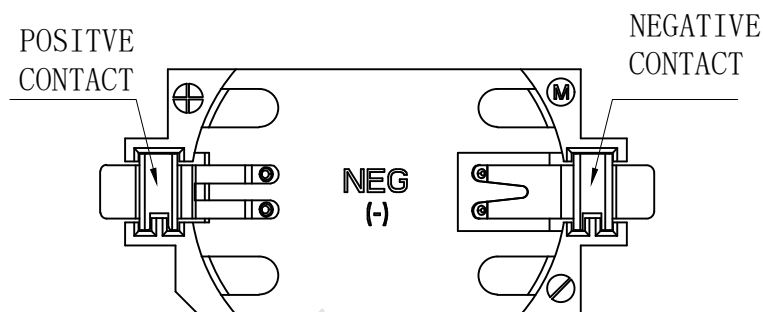

MOUNTING PAD & HOLE DETAIL

Unless Otherwise specified tolerance		
X. ±0.35 X.XX: ±0.20 X.X: ±0.25 X.XXX: ±0.15		
SCALE: As Shown	UNIT: mm	
DRAW Mo Guo Xuan	DATE 03/15/2019	TITLE: Coin Cell Holders For CR2477
CHECK BobYang	DATE 03/15/2019	
 3rd ANGLE PROJECTION		DRAWING NO: BT-M-G5-R-CR2477A
		PRODUCT NO: BT-M-G5-R-CR2477A

REV	△ Add packing information	22/03/2022
	DESCRIPTION	DATE