



HSF

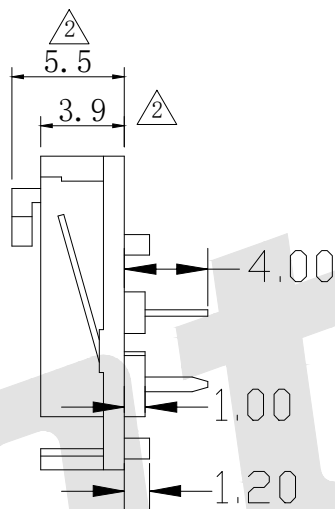

RoHS

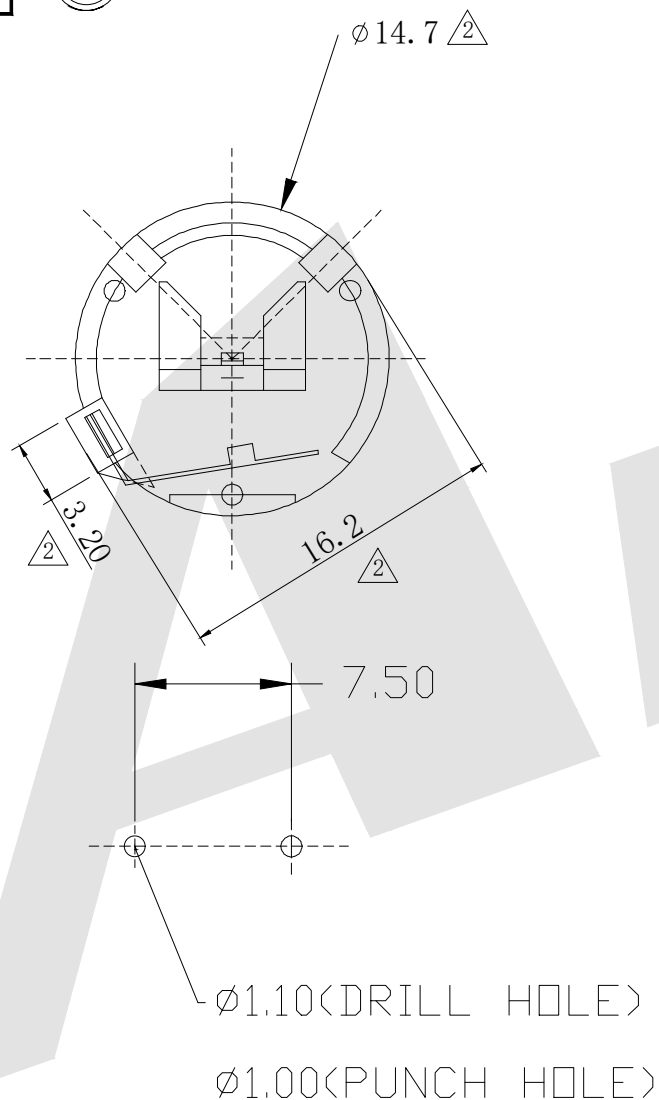

Note:

1. Material:

- a. Housing: PBTVO+GF BK
- b. Contact: C5191
- c. Surface Plating: Sn 10u"

2. Electric:

- a. Contact Resistance: 30 Milliohms Max.
- b. Insulation Resistance: 1000 Mega Ohms Min.
- c. Dielectric Voltage: 500 V AC One Sec Level
- d. Operating Temperature: -55° To +105°

Order code:

BT — S — SN — R — CR1220B
① — ② — ③ — ④ — ⑤

① BT: Coin Cell Holders

② Apperance for the product

S: 180 TYPE

③ Contact PIating

SN: Tin

G0: Gold flash

G1: 3U" Gold

G2: 5U" Gold

G3: 10U" Gold

G4: 15U" Gold

G5: 30U" Gold

④ Packing method

A: Tray packing

 
R: Tape & reel packing

⑤ Product number

CR1220B

Unless Otherwise specified tolerance
X. ± 0.35 X. XX: ± 0.20
X. X: ± 0.25 X. XXX: ± 0.15

SCALE: As Shown UNIT: mm
DRAW Mo Guo Xuan DATE 13/03/2019
CHECK BobYang DATE 13/03/2019

**Antenk**®

TITLE: Coin Cell Holders For CR1220

DRAWING NO: BT-S-SN-R-CR1220B

PRODUCT NO: BT-S-SN-R-CR1220B

② Revise Dimensions

08/02/2022

change BT-S-SN-CR1220A to BT-S-SN-R-CR1220B

REV DESCRIPTION

DATE